


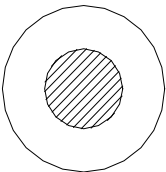

Datasheet

Product Name:	UL1429 24AWG
Product Discription:	UL1429 24AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	150V	Conductor	Stranded Tinned Copper		
Rated Temperature:	80°C	Size(AWG)	24		
Reference Standard:	UL758,UL1581	Construction(±0.008mm)	7/0.20		
Cross Section 		Stranded Dia.(mm)Ref.	0.6		
		Insulation Material	XLPVC		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.26		
		Insulation Dia.(±0.06mm)	1.12		

Marking	Remark:
E148000  AWM STYLE 1429 24AWG 80°C 150V VW-1 --- C  AWM I A 80°C 150V FT1 -F- -LF- PC10 LTK	8775323 Red 8775327 Blue 8775345 Grey 8775349 Violet 8775311 Black 8775336 White 8775333 Yellow 8775320 Brown 8775339 Green 8775342 Orange

Applications	Characteristics	Customer Approve
For Internal Wiring of Appliances or Electronic Equipment	Test Item	Standard Value
	Test Material	XLPVC(ROHS)
	Max.DC Resistance(20°C Ω/km)	94.2(MAX)
	Vol. Tesr(AC.V.60S) (V)	1500
	Flammability Test	VW-1

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Lisa	Jason	18/05/2015

Seal & Stamp

Signature:

Date: