

#4130 - 2 Core Flat Loudspeaker Cable 1.5mm²



Part NO: #4130

Product Code: RGW-1884

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2Cores

Cable Construction

| | |
|---------------------|----------------------|
| Conductor | Bare Copper |
| Construction | 0.1 ± 0.008 x 63 x 3 |
| Standard Dia.(mm) | 1.76 |
| Insulation | Trans PVC |
| Thickness | 0.62 |
| Insulation Dia.(mm) | 3.0 ± 0.1 x 2C |
| Insulation Color | Trans PVC |

Marking

Coloured Stripe (Black) one core


PACKAGING

100M/Reel

Revision History

A0-1

Design

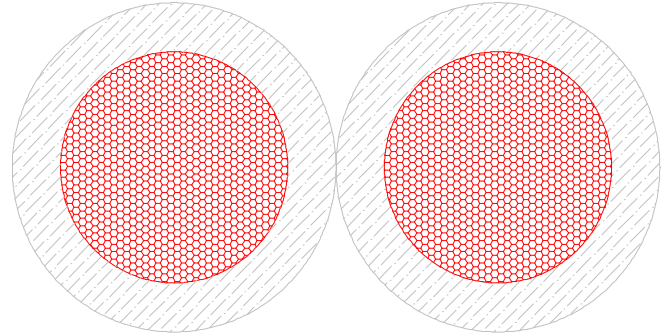

A: Electrical Characteristics

| | |
|---|--------|
| Max.Conductor DC Resistance at 20°C (Ω /Km) | <12.54 |
| Min.Insulation DC Resistance at 20°C (MΩ *Km) | >200 |
| Rated Temperature(°C) | 80 |
| Rated Voltage (V) | 300 |

RoHS GUIDELINE

We operate according to the following standards

| Control Item | Standard | Testing Method | Testing Equipment |
|--------------------------------------|-----------|-----------------|-------------------|
| Cadmium content (Cd) | <0.01% | EN1122 | ICP-AES |
| Lead content (Pb) | <0.1% | EPA3050B | ICP-AES |
| Mercury content (Hg) | <0.1% | EPA3052 | ICP-AES |
| Chromium (VI) content | <0.1% | EPA3060(UN-VIS) | ICP-AES |
| Polybrominated Biphenyls(PBB) | Forbidden | GC/MS | |
| Polybrominated Diphenyl Ether (PBDE) | Forbidden | GC/MC | |

Date: 2013-03-06

Page: 1 / 1