

Datasheet

ENGLISH


RS PRO, 12 V dc, 6000 gcm, Brushed DC Geared Motor, Output Speed 98 rpm

Stock No: 238-9670



Specifications:

Output Speed	98 rpm
Supply Voltage	12 V dc
Maximum Output Torque	6000 g.cm
DC Motor Type	Brushed
Shaft Diameter	6mm
Power Rating	19.8 W
Gearhead Type	Spur
Length	80.7mm
Width	35.5mm
Current Rating	2.81A
Weight	255g

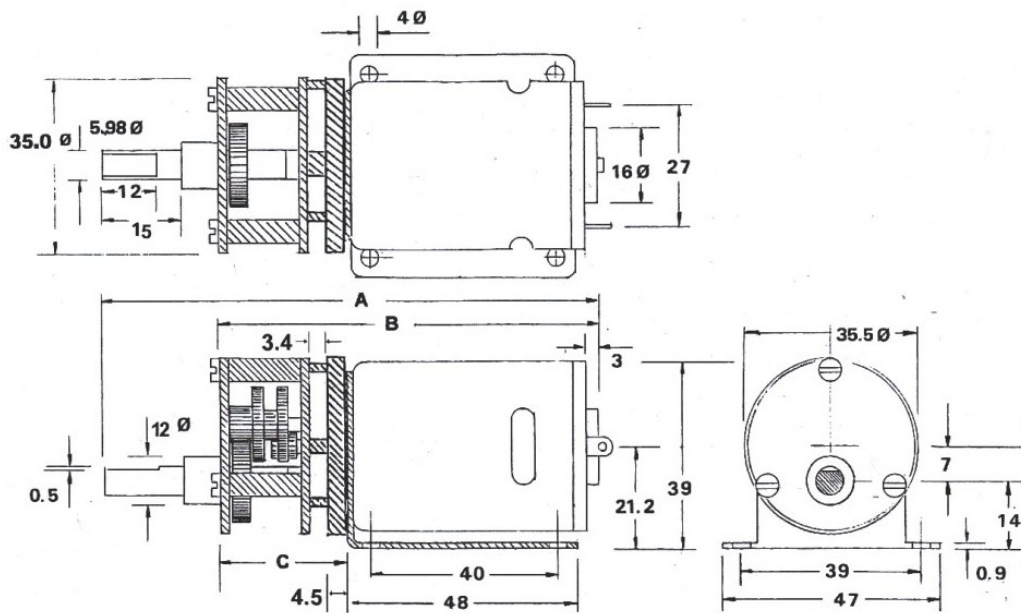

Ratio	A	B	C
148:1	105.7mm	80.7mm	28.7mm

Gearbox Housing material	Metal
Backlash at no-load	< 2°
Bearing at output	Sleeve bearings
Radial load (10mm from flange)	< 1 kgf
Shaft axial load	< 0.7 kgf
Shaft press fit force max	< 20 kgf
Radial play of shaft	< 0.05mm
Thrust play of shaft	< 0.35mm

Reduction Ratio	Rated tolerance Torque	Max momentary Tolerance Torque	Efficiency
1/150	6 kgf-cm Max.	18 kgf-cm	59%

Reduction Table RPM SUPPLY VOLTAGE	4.5v	6v	9v	12v	15v
238-9670	37	49	74	98	123

Note: Motor speeds may vary by (+) or (-) 12.5%