


Technical data sheet

Article number:
169-22850

IWS8.5

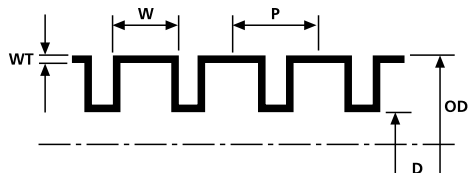

Product Group	Non-Metallic Conduits
Product Family	IWS Polyamide 6
Material	Polyamide 6 (PA6)
Colour	Black (BK)
Bending Radius min. (R)	15 mm
Diameter (D)	8.4 mm
Flammability	UL 94 HB, FMVSS 302
Halogen-free	Yes
Inside Ø (ID)	8.4 mm
Length (L)	50 m
Nominal Ø	8.5 mm
Operating Temperature	-40 °C to +120 °C
Outside Ø (OD)	11.7 mm
Pack Cont.	50 m
Package Content packed in	metre

HF ✓

RoHS ✓