

## LEUCA MID

H 60532 3D K 4 S3 SRC ESD




### SPECIFICATIONS

|                  |   |
|------------------|---|
| UPPER            | water-repellent smooth full grain   |
| LINING           | BIFRESH PLUS 3D lining with high breathability and top abrasion resistant |
| TOE-CAP          | composite   |
| NAIL PROTECTION  | Zero Perforation fabric, metal-free, ESD                                  |
| SOLE             | dual density PU   |
| INSOLE           | SUPPORT ACTIVE ESD  |
| SIZES            | 36/49   |
| FIT              | Mondopoint 12   |
| SAFETY NORMS     | EN ISO 20345:2011   |
| WEIGHT (SIZE 42) | 1,32 Kg   |

### WORK ENVIRONMENTS

Heavy Industry / Construction / Automotive / Logistics / Electronics / Gas and Explosives / Light Industry / Engineering / Mechatronics

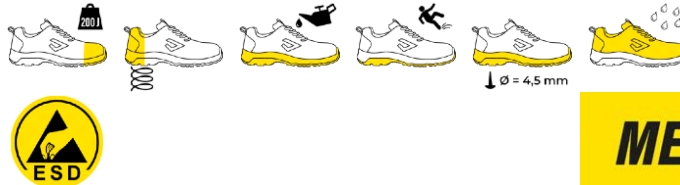


### METAL FREE

### DESCRIPTION

LEUCA MID is a versatile ESD boot, class protectio S3 SRC, made of water-repellent and smooth full grain, decorative stitchings

### TOE-CAP

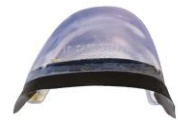

### COMPONENTS

Polyurethane insole with activated carbons ensures maximum hygiene avoiding the proliferation of fungi and bad odours. Anti-static, anatomic, provides excellent support along the plantar arch, ensures maximum comfort and absorption of the impact energy. Made with a compounds of EPA material (low electrical resistance)

### INSOLE



Impact resistant up to 200J according to EN 20345. Non-magnetic, thermal insulating, reduced thickness, 50% lighter than steel toe cap

### STANDARD LABEL



### PLUS

BIFRESH PLUS: Three-dimensional Polyester lining with high abrasion resistance and breathability



Calzaturificio 5Bi S.r.l.  
Via Trani, 94-100  
76121 Barletta (BT)

H 60532 3D K 4

42

bicap.it

S3 SRC



Year and month of manufacture

Lot / Batch Number

EN ISO 20345:2011



do not re-use