


PXMBNI16FBF04ASCPG9 Datasheet



Product Name // M16 Series A Code Brass Nickel Plated
PG9 Flex Body 4 Contact Socket

[View Product Page](#)

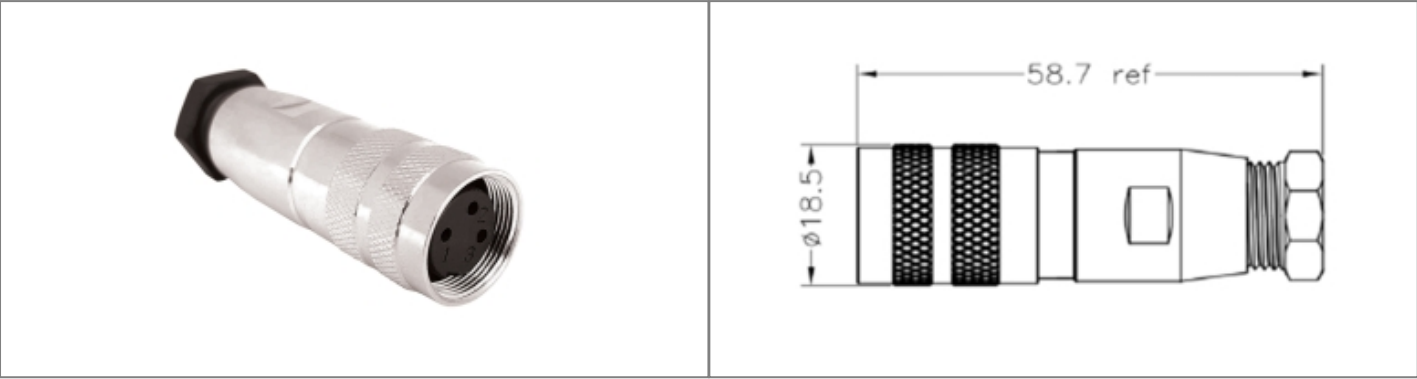

// Product Description:

M16 Series Brass Nickel Plated Flex Body Connectors

Water and dustproof to IP67 when mated with compatible connector

A Code

Socket only

3, 4, 5, 6, 8, 12 Contact

Solder Terminals

Mate with M16 Series Inline Body and Panel Mount Connectors

// General Information:

Product Display Title:

Product Family:

Product Series:

Change Notes:

Body Material:

Contact Type:

Coupling Type:

Current Max:

Diameter Over Coupling Ring Mm:

Function:

Ip Rating:

M12 Series Mounting Nut:

Max Operating Temperature:

Min Operating Temperature:

Number Of Contacts:

Pin Layout Code:

Thread Size:

Voltage Max:

M16 Series Brass Nickel Plated Flex Body Connectors

Circular Automation Connectors

M16 Series

PRODUCT-MOQ-ADJUSTMENT

Brass - Nickel Plated

Socket Contact

Screw

7A

18.5mm

Flex Cable Connector Body

IP67

PG9

+80°C

-25°C

4 Contacts

A Code

M16 x 0.75

250V

// Product PDF Links

M16 Series automation connectors...

// Product 3D CAD Model Links

PXMBNI16FBF04ASCPG93D CAD Model