


PRODUCT-DETAILS

# SRX-SRN12630X

## SRX-SRN12630X Control and Automation Board

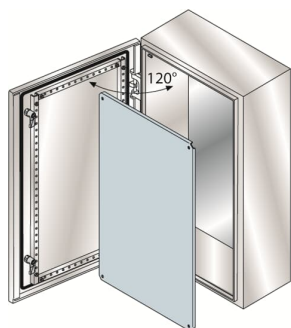

### General Information

Extended Product Type	SRX-SRN12630X
Product ID	SRN12630X
EAN	8015646774903
Catalog Description	SRX-SRN12630X Control and Automation Board
Long Description	Enclosure blind door plate stainless steel 1200x600x300

### Technical

Suitable for Product Class	SRX
Number of Flange Openings	2
Cover Plate Type	Door
Enclosure Type NEMA	Type4X
Mounting Type	Surface mounted (plaster)
Door Type	Single
Construction Material	Stainless steel
Door Surface Finishing	Opaque
Housing Material	Stainless steel
Thickness	Cabinet Plate 1.2 mm Door Plate 1.2 mm

### Environmental

Degree of Protection	IP66
Protection Class	Grounded
Environmental Information	1STM6041230001

### Dimensions

Product Net Width	600 mm
Product Net Height	1200 mm
Product Net Depth / Length	300 mm
Product Net Weight	45.3 kg
Built-In Depth (t <sub>2</sub> )	232 mm

### Container Information

Package Level 1 Units	box 1 piece
Package Level 1 Width	0.62 m
Package Level 1 Height	0.33 m
Package Level 1 Depth / Length	1.22 m
Package Level 1 Gross Weight	45.8 kg
Package Level 1 EAN	8015646774903

### Ordering

Minimum Order Quantity	1 piece
Customs Tariff Number	85381000
Country of Origin	Italy (IT)

### Certificates and Declarations (Document Number)

Declaration of Conformity - CE	No declaration needed
Environmental Information	1STM6041230001
Instructions and Manuals	1STM6041230001
RoHS Information	1STC860027

### Popular Downloads

Data Sheet, Technical Information	1STC804021D0201
Instructions and Manuals	1STM6041230001

### Classifications

ETIM 7	EC000058 - Empty cabinet
ETIM 8	EC000058 - Empty cabinet
WEEE Category	Product Not in WEEE Scope

---

## Categories

---

Low Voltage Products and Systems → Enclosures → General Purpose Enclosures → Metal Enclosures → SRX

