


T5 LED BARS



POWER W	KELVIN	LUMEN lm	MEASURES mm	BEAM °	CODE	EAN	PACKAGING	ENERGY CLASS
4	3000	300	1	160	LD3BAR03042	8031453022815	10 / 30	
4	4000	320	1	160	LD3BAR03043	8031453022822	10 / 30	
8	3000	640	2	160	LD3BAR06082	8031453022839	10 / 30	
8	4000	680	2	160	LD3BAR06083	8031453022846	10 / 30	
16	3000	1300	3	160	LD3BAR12162	8031453022853	10 / 30	
16	4000	1350	3	160	LD3BAR12163	8031453022860	10 / 30	

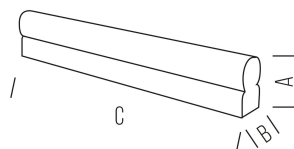

DIMENSIONS	A	B	C
1	36	22,5	317
2	36	22,5	578
3	36	22,5	1178

- MODULAR LED SYSTEM TO CREATE A CONTINUOUS LINEAR LIGHT SOURCE
- INTEGRATED CONNECTOR FOR DIRECT CONNECTION WITHOUT SHADOW GAPS
- MAXIMUM LOAD 110W. CORRESPONDING TO 7 X 16W LUMINAIRES (8.4M)
- SUPPLIED WITH POWER CABLE AND WALL FIXING CLIP
- INTERCONNECTING FLEX CABLE SUPPLIED SEPARATELY (BAG WITH 5PCS)