


Supply plate VMPA-FB-SP-M12-V

Part number: 8204604

FESTO

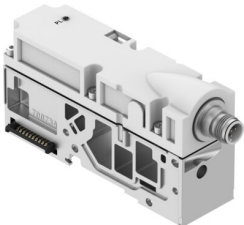

 [General operating condition](#)

Data sheet

Feature	Value
Max. power supply	4 A
Nominal operating voltage DC	24 V
Permissible voltage fluctuations	+/-25%
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65
Ambient temperature	-5 °C ... 50 °C
Product weight	200 g
Electrical connection	5-pin M12x1 round plug connector
Note on materials	RoHS compliant
Material cover	Reinforced PA
Material housing	Die-cast aluminium