


FORGOS® TELEPHONY


ADAPTERS - MODULES - SOCKETS

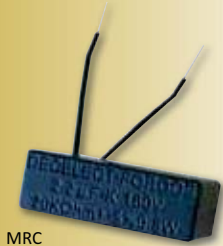

MRC



AD4550

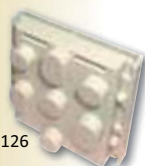

126

Designation	Characteristics	Reference
45 x 50 adapter	45x45 to 50x50 format adapter	AD4550
RC module	Resistance 20 Kohms Capacitance 2,2 µF	MRC
Anti-moisture socket	For French phone socket and BRI Possible mounting on "DIN" metal rail	126

European universal adapter



VADAP




134

Designation	Characteristics	Reference
Allows PC connexion to the telephone line of the country	For : Holland - Belgium France - UK Germany - Italy	134
Adapters case	All countries	VADAP

TELEPHONE CORDS

Telephone handset cords

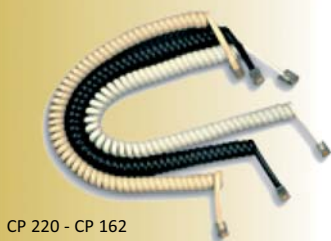

CP 220 - CP 162

Designation	Characteristics	Colours	Cable length	Reference
Large length telephone handset cords	Crossed wiring	Black	3 m	CP220341
	fully compatible	Ivory	3 m	CP220342
Equipment	with standard	Black	5 m	CP220343
Plug/plug RJ9 (4/4)	telephone handsets	Ivory	5 m	CP220344
Standards phone handset cord	Crossed wiring	Black	1,50 m	CP162446N
	fully compatible	Ivory		CP162446I
Long. 300 mm (not stretched)	with standard	White		CP162446B
Equipment Plug/plug RJ9 (4/4)	telephone handsets			
Matre handset cords	Crossed wiring	White		4TC505-30-B
	fully compatible	Ivory		4TC505-30-I
Long. 300 mm (not stretched)	with standard	Black		4TC505-30-N
Equipment Plug/plug	"MATRA"	Bead		4TC505-30-A

RJ11 telephone handset cords



CT6430N

Flat cable	Cable + Plug	Length	Terminal B french connector	Terminal B Plug (male)	Connected pins only	Reference
4 cond.	Ivory	3 m	RJ 11 straight wiring	RJ11	A 2 → 2 3 → 3 B 4 → 4 5 → 5	CT6430I
4 cond.	Black	3 m	RJ 11 straight wiring	RJ11		CT6430N

Other length on request.