



Einhell

PROFESSIONAL



Professional
Cordless Angle Grinder

AXXIO 18/115

Item No.: 4431154

Ident No.: 21034

Bar Code: 4006825672046

The Einhell cordless angle grinder AXXIO 18/115 is the ideal helper in any workshop. As a member of the Power XChange family, the battery can be used in all devices of the system series. The device is driven by a PurePOWER Brushless motor for enhanced power and longer runtime. Once you register online, the brushless motor has a 10-year guarantee. Soft start, restart and overload protection are used for safety (including cut-off guard). The slim design, as well as the decoupling of the motor and gearbox, the flexibly mountable additional handle and the dust-proof construction ensure pleasant working. Delivery does not include battery, charger or cutting discs (Ø 115 mm).

Features & Benefits

- Member of the Power X-Change family, 1x 18 V battery required
- Brushless motor – more power and longer running time
- PurePOWER Brushless – 10-year motor guarantee after registration
- Dust-proof construction for long service life
- Removable dust guards for easy cleaning
- Soft-start and protection against accidental restarts enhance user safety
- Overload protection for durability
- Quick-adjust disc guard for flexible use
- Cut-off guard for maximum safety during cutting
- Additional handle can be assembled in 2 positions as required
- Supplied without cutting disc
- Delivery without battery or charger (available separately)



PXC BATTERY


 **BATTERY & CHARGER NOT INCLUDED**

Technical Data

- | | |
|-------------------------------------|------------------------|
| - Max. cutting depth | 28 mm |
| - No-load speed (idle speed) Max. | 8500 min ⁻¹ |
| - Disc size | 115 mm |
| - Mains supply charger | 220-240 V 50 Hz |

Logistic Data

- | | |
|--------------------------------------|--------------------|
| - Gross weight (kg) | 2.46 |
| - Gross weight of export carton | 9.13 kg |
| - Product weight (kg) | 1.73 |
| - Pieces per export carton | 4 pcs |
| - Container quantity (20"/40"/40"HC) | 4100 8200 9792 |
| - Dimensions Export Carton | 355 x 340 x 225 mm |
| - Dimensions single packaging | 357 x 153 x 150 mm |

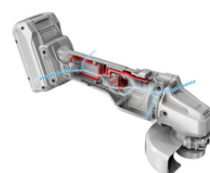

DUST PROOF




TOOLLESS GUARD

PXC BATTERY


 **BATTERY & CHARGER NOT INCLUDED**

**BEST
PERFORMANCE
≥ 2.5 Ah
BATTERY**

18 V

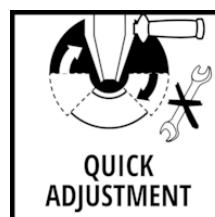

**QUICK
ADJUSTMENT**

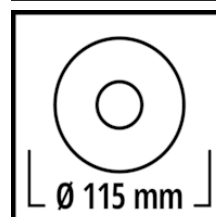

Ø 115 mm

Available as special accessories



E-Case S-F
System Carrying Case
Item No.: 4540011
Bar Code: 4006825653991
Einhell Accessory



E-Case M
System Carrying Case
Item No.: 4540021
Bar Code: 4006825667721
Einhell Accessory



E-Case M SEALED
System Carrying Case
Item No.: 4540053
Bar Code: 4006825687071
Einhell Accessory



PXC 18V 3,0Ah
Battery
Item No.: 4511341
Bar Code: 4006825590593
Einhell Accessory



PXC 18V 5,2Ah
Battery
Item No.: 4511437
Bar Code: 4006825616606
Einhell Accessory



PXC+ 18V 4-6Ah MULTI
Battery
Item No.: 4511502
Bar Code: 4006825644210
Einhell Accessory



PXC+ 18V 5-8Ah MULTI
Battery
Item No.: 4511600
Bar Code: 4006825665055
Einhell Accessory



PXC+ 18V 4,0Ah SEALED
Battery
Item No.: 4511627
Bar Code: 4006825673227
Einhell Accessory



2x 18V 5,2Ah PXC-Twinpack
Battery
Item No.: 4511526
Bar Code: 4006825656695
Einhell Accessory



18V 3Ah PXC Plus Twinpack
Battery
Item No.: 4511631
Bar Code: 4006825673692
Einhell Accessory



2x2 Power X-Quattrocharger 4A
Charger
Item No.: 4512102
Bar Code: 4006825649536
Einhell Accessory



Power X-Car Charger 3A
Charger
Item No.: 4512113
Bar Code: 4006825655377
Einhell Accessory



18V 2,5Ah PXC Starter Kit
PXC-Starter-Kit
Item No.: 4512097
Bar Code: 4006825646962
Einhell Accessory



2x 4,0Ah & Twincharger Kit 1
PXC-Starter-Kit
Item No.: 4512112
Bar Code: 4006825655766
Einhell Accessory



E-Case L with wheels
System Carrying Case
Item No.: 4540014
Bar Code: 4006825660562
Einhell Accessory



E-Case S-F SEALED
System Carrying Case
Item No.: 4540052
Bar Code: 4006825687033
Einhell Accessory



E-Case L with wheels SEALED
System Carrying Case
Item No.: 4540054
Bar Code: 4006825687088
Einhell Accessory



PXC 18V 4,0Ah
Battery
Item No.: 4511396
Bar Code: 4006825610376
Einhell Accessory



PXC+ 18V 3,0Ah
Battery
Item No.: 4511501
Bar Code: 4006825644197
Einhell Accessory



PXC+ 18V 4,0Ah
Battery
Item No.: 4511553
Bar Code: 4006825660869
Einhell Accessory



PXC+ 18V 3,0Ah SEALED
Battery
Item No.: 4511618
Bar Code: 4006825672794
Einhell Accessory



2x18V 4,0Ah PXC-Twinpack CB
C1
Battery
Item No.: 4511489
Bar Code: 4006825638578



18V 4Ah PXC Plus Twinpack
Battery
Item No.: 4511629
Bar Code: 4006825673685
Einhell Accessory



Power X-Twincharger 3A
Charger
Item No.: 4512069
Bar Code: 4006825629729
Einhell Accessory



Power X-Fastcharger 4A
Charger
Item No.: 4512103
Bar Code: 4006825650228
Einhell Accessory



18V 4,0Ah PXC Starter Kit C1
PXC-Starter-Kit
Item No.: 4512042
Bar Code: 4006825613704
Einhell Accessory



2x 5,2Ah & Twincharger Kit
PXC-Starter-Kit
Item No.: 4512108
Bar Code: 4006825652376
Einhell Accessory



18V 4-6Ah & 6A Boostcharger
PXC-Starter-Kit
Item No.: 4512143
Bar Code: 4006825667653
Einhell Accessory

Battery-Running-Times

Battery Capacity	2.0 Ah	3.0 Ah	4.0 Ah	5.2 Ah	6.0 Ah	8.0 Ah
Performance	36 pcs.	54 pcs.	72 pcs.	94 pcs.	108 pcs.	144 pcs.

Max. cutting capacity per battery charge: Round steel Ø 12 mm