



The Roshni Low Profile (RoLP) is the fire alarm markets leading conventional sounder, although it finds uses in many applications, such as security, general signalling and process alarms.

With its recognisable body, wide operating voltage and international reputation for quality, the RoLP is a flexible sounder suitable for use in most applications.


## Features

- 102dB(A) sound output
- 32 tones (user selectable)
- Two stage alarm
- Automatic synchronisation

## Benefits

- Ideal for general signalling and Fire use
- Fire approved and general signalling tone options
- Alert and alarm function
- Improved tone clarity, reducing confusion

## Dimensions

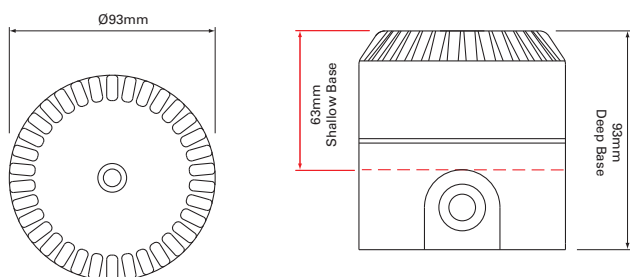

## Technical Specification

<b>Voltage</b>	9-15Vdc 18-28Vdc
<b>Current</b>	12mA (Typical Tone 3)
<b>Sound Output</b>	102dB(A) (Typical Tone 3)
<b>Tones</b>	32
<b>Volume</b>	Control 10dB
<b>Monitoring</b>	Reverse polarity
<b>Temperature</b>	- 25°C to + 70°C
<b>Protection</b>	IP54 (s)* IP65 (d)*
<b>Construction</b>	ABS
<b>Weight</b>	0.25Kg
<b>Colours</b>	Red or white

(s)\* Shallow Base  
(d)\* Deep / U Base

RoLP White



## Catalogue Numbers

Reference	Cat No	Description
ROLP/SV/R/S	540501FULL-0389X	RoLP, Shallow Base, Red Body
ROLP/SV/W/S	540502FULL-0406X	RoLP, Shallow Base, White Body
ROLP/SV/R/D	540503FULL-0403X	RoLP, Deep Base, Red Body
ROLP/SV/W/D	540504FULL-0410X	RoLP, Deep Base, White Body
ROLP/SV/R/U	540505FULL-0390X	RoLP, U - Base, Red Body
ROLP/SV/W/U	540506FULL-0441X	RoLP, U - Base, White Body

