

## 1.11 DIN Rail Enclosures & PSU's

### Enclosures

- IP56 rated protection
- Insulation class II
- Transparent Lid
- Material GW PLAST 120 °C
- -25 °C to 60 °C Installation temperature range
- Sealed hinged lid screws
- DIN Rails mounted on steel plate
- Pre-drilled antenna hole
- Gland for PSU lead

### Power Supplies

- Rail mounted 12v power supply
- 110-240Vac Input
- 12V 1A Output

The DIN rail enclosures provide an ideal solution for mounting DIN rail modules.


The enclosures are available in two sizes;

2 Rail Internal dims 300 x 220 x 120mm

3 Rail Internal dims 240 x 190 x 90mm

They can be supplied bare (ENC-DIN3 or ENC-DIN2) or fitted with DIN Rails attached to a mounting plate and a 12v power supply (ENC-DA3R1 or ENC-DA2R1).

The DIN Rail Modules can plug directly in to the assemblies, alternatively custom assemblies can be supplied on request.

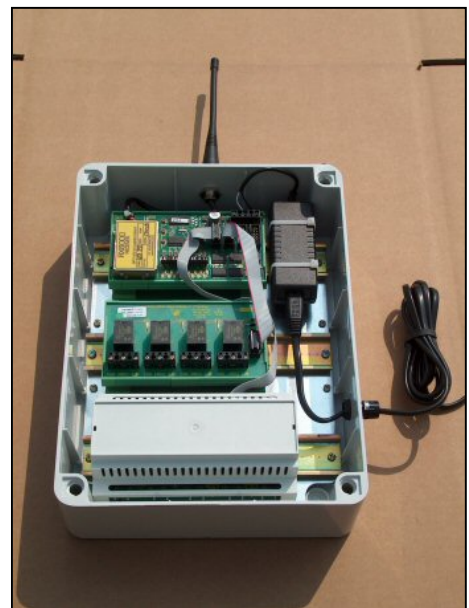

Part No	Description
ENC-DA3R1	DIN Rail Encl Assy, three mounting Rails & PSU
ENC-DA2R1	DIN Rail Encl Assy, two mounting Rails & PSU
PSU12V1AIN-IP	Power Supply Unit 110-240Vac input, 12V 1A Output