


Geberit Mapress flat gasket, EPDM, black

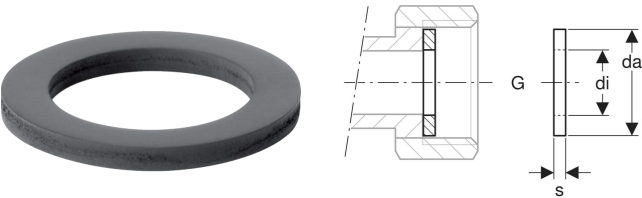

Example image

APPLICATION PURPOSES

- For cold and hot potable water
 - For cooling and heating water without antifreeze agent
 - For service water and process water
 - For treated water
 - For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
 - For seawater
 - For extinguishing water (wet)
 - For sprinklers (wet)
 - For chemicals and technical liquids
 - For compressed air (oil purity class 0–3)
 - For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding
 - For flat-sealing Geberit Mapress unions

TECHNICAL DATA

Operating temperature	0–100 °C
Product material	EPDM

Art. no.	G	de, ø mm	di, ø mm	s mm
These articles are suitable for the following system: Geberit Mapress Stainless Steel				
90080	1/2	18	10	2
90081	3/4	24	13	2
90082	1	30	20	2
90083	1 1/4	39	26	2

Art. no.	G "	de, ø mm	di, ø mm	s mm
90084	1 1/2	45	32	2
90085	1 3/4	50	39	2
90086	2 3/8	66	51	3
90220	2 1/2	72	54	3
90079	2 3/4	78	57	3
90088	3	85	76	3
90089	3 1/2	97	84	3

These articles are suitable for the following system: **Geberit Mapress Carbon Steel**

90080	1/2	18	10	2
90081	3/4	24	13	2
90082	1	30	20	2
90083	1 1/4	39	26	2
90084	1 1/2	45	32	2

Art. no.	G "	de, ø mm	di, ø mm	s mm
90085	1 3/4	50	39	2
90086	2 3/8	66	51	3
90220	2 1/2	72	54	3
90079	2 3/4	78	57	3
90088	3	85	76	3
90089	3 1/2	97	84	3

These articles are suitable for the following system: **Geberit Mapress CuNiFe**

90080	1/2	18	10	2
90081	3/4	24	13	2
90082	1	30	20	2
90083	1 1/4	39	26	2
90084	1 1/2	45	32	2
90085	1 3/4	50	39	2

Art. no.	G "	de, ø mm	di, ø mm	s mm
90086	2 3/8	66	51	3
90220	2 1/2	72	54	3
90079	2 3/4	78	57	3
90088	3	85	76	3
90089	3 1/2	97	84	3

These articles are suitable for the following system: **Geberit Mapress Therm**

90080	1/2	18	10	2
90081	3/4	24	13	2
90082	1	30	20	2
90083	1 1/4	39	26	2
90084	1 1/2	45	32	2
90085	1 3/4	50	39	2
90086	2 3/8	66	51	3

Art. no.	G "	de, ø mm	di, ø mm	s mm
90220	2 1/2	72	54	3
90079	2 3/4	78	57	3
90088	3	85	76	3
90089	3 1/2	97	84	3

These articles are suitable for the following system: **Geberit Mapress Copper**

90080	1/2	18	10	2
90081	3/4	24	13	2
90082	1	30	20	2
90083	1 1/4	39	26	2
90084	1 1/2	45	32	2
90085	1 3/4	50	39	2
90086	2 3/8	66	51	3
90220	2 1/2	72	54	3

Art. no.	G "	de, ø mm	di, ø mm	s mm
90079	2 3/4	78	57	3
90088	3	85	76	3
90089	3 1/2	97	84	3