
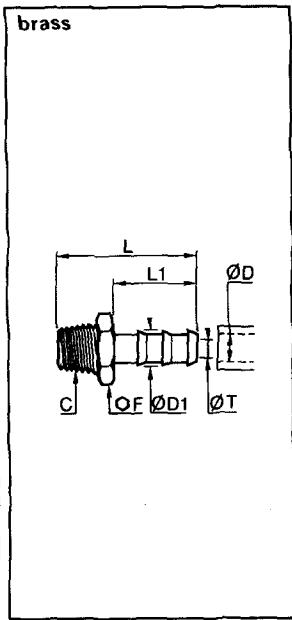




tailpiece adaptors

0123 tailpiece adaptor for rubber hose, male BSP taper

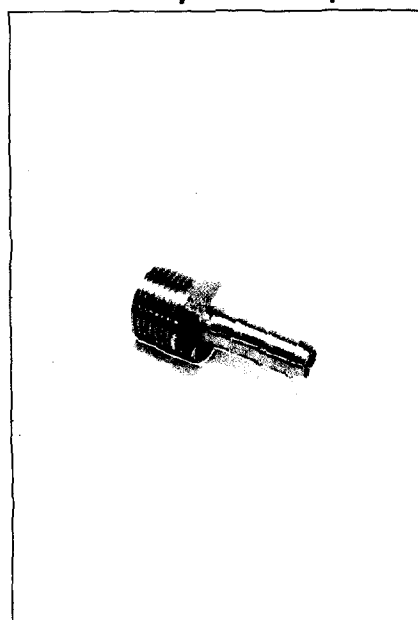

| ØD | C | | ØD1 | F | L | L1 | T mini | Δkg |
|----|-----|------------|------|----|------|------|-----------|-------|
| 4 | 1/8 | 0123 04 10 | 6 | 10 | 34 | 22,5 | 3,3 | 0,008 |
| 6 | 1/8 | 0123 06 10 | 8 | 10 | 34 | 22,5 | 5 | 0,009 |
| 7 | 1/8 | 0123 07 10 | 9 | 10 | 34 | 22,5 | 5 | 0,009 |
| 7 | 1/4 | 0123 07 13 | 9 | 14 | 38,5 | 22,5 | 6 | 0,018 |
| 7 | 3/8 | 0123 07 17 | 9 | 17 | 39 | 22,5 | 6 | 0,023 |
| 10 | 1/8 | 0123 10 10 | 12,2 | 13 | 34 | 22,5 | 5 | 0,014 |
| 10 | 1/4 | 0123 10 13 | 12,2 | 14 | 38,5 | 22,5 | 7 | 0,021 |
| 10 | 3/8 | 0123 10 17 | 12,2 | 17 | 39 | 22,5 | 9,5 | 0,023 |
| 12 | 3/8 | 0123 12 17 | 14 | 17 | 46 | 29,5 | 11 | 0,026 |
| 13 | 1/4 | 0123 13 13 | 15 | 17 | 45,5 | 29,5 | 7 | 0,027 |
| 13 | 3/8 | 0123 13 17 | 15 | 17 | 46 | 29,5 | 11 | 0,027 |
| 13 | 1/2 | 0123 13 21 | 15 | 22 | 50,5 | 29,5 | 12 | 0,047 |
| 16 | 3/8 | 0123 16 17 | 18,5 | 19 | 54,5 | 38 | 11 | 0,040 |
| 16 | 1/2 | 0123 16 21 | 18,5 | 22 | 59 | 38 | 14 | 0,056 |
| 16 | 3/4 | 0123 16 27 | 18,5 | 27 | 62 | 38 | 15 | 0,082 |
| 19 | 3/8 | 0123 19 17 | 21,5 | 22 | 54,5 | 38 | 11 | 0,046 |
| 19 | 1/2 | 0123 19 21 | 21,5 | 22 | 59 | 38 | 14 | 0,058 |
| 19 | 3/4 | 0123 19 27 | 21,5 | 27 | 62 | 38 | 18 | 0,083 |
| 25 | 3/4 | 0123 25 27 | 26,7 | 27 | 62 | 38 | 18 | 0,083 |
| 25 | 1" | 0123 25 34 | 27 | 36 | 65 | 38 | 24 | 0,124 |
| 32 | 1" | 0123 32 34 | 34,5 | 36 | 70 | 43 | 24 | 0,144 |



0136 tailpiece adaptor for Legris nylon tube, male taper

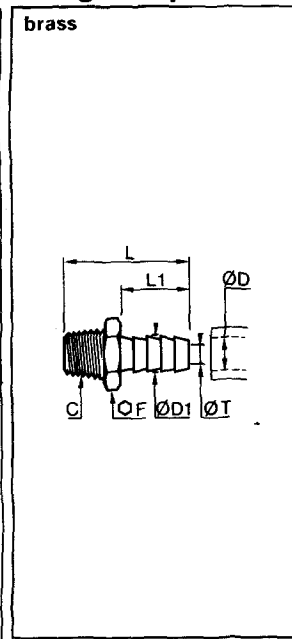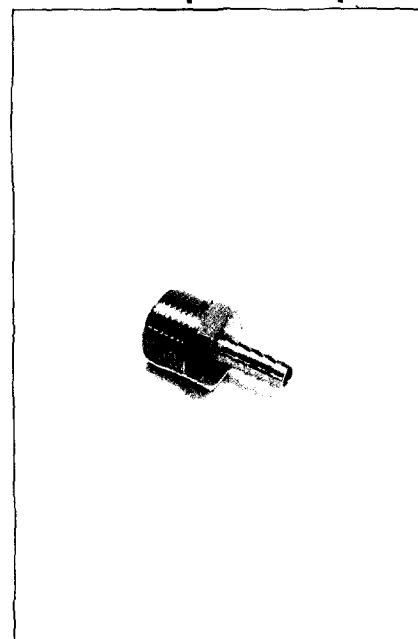

| ØD | C | | ØD1 | F | L | L1 | T mini | Δkg |
|----|-----|------------|------|----|------|----|-----------|-------|
| 4 | 1/8 | 0136 06 10 | 4,3 | 10 | 26,5 | 15 | 2 | 0,007 |
| 4 | 1/4 | 0136 06 13 | 4,3 | 14 | 31 | 15 | 2 | 0,015 |
| 4 | 3/8 | 0136 06 17 | 4,3 | 17 | 31,5 | 15 | 2 | 0,020 |
| 6 | 1/8 | 0136 08 10 | 6,4 | 10 | 26,5 | 15 | 4 | 0,007 |
| 6 | 1/4 | 0136 08 13 | 6,4 | 14 | 31 | 15 | 4 | 0,015 |
| 6 | 3/8 | 0136 08 17 | 6,4 | 17 | 31,5 | 15 | 4 | 0,020 |
| 8 | 1/4 | 0136 10 13 | 8,4 | 14 | 31 | 15 | 6 | 0,016 |
| 8 | 3/8 | 0136 10 17 | 8,4 | 17 | 31,5 | 15 | 6 | 0,020 |
| 8 | 1/2 | 0136 10 21 | 8,4 | 22 | 36 | 15 | 6 | 0,039 |
| 10 | 1/4 | 0136 12 13 | 10,7 | 14 | 36 | 20 | 7 | 0,019 |
| 10 | 3/8 | 0136 12 17 | 10,7 | 17 | 36,5 | 20 | 8 | 0,023 |
| 10 | 1/2 | 0136 12 21 | 10,7 | 22 | 41 | 20 | 8 | 0,040 |
| 12 | 1/4 | 0136 14 13 | 12,7 | 14 | 36 | 20 | 7 | 0,019 |
| 12 | 3/8 | 0136 14 17 | 12,7 | 17 | 36,5 | 20 | 10 | 0,023 |
| 12 | 1/2 | 0136 14 21 | 12,7 | 22 | 41 | 20 | 10 | 0,042 |
| 12 | 3/4 | 0136 14 27 | 12,7 | 27 | 44 | 20 | 10 | 0,072 |
| 13 | 3/8 | 0136 16 17 | 13,7 | 17 | 36,5 | 20 | 11 | 0,023 |
| 13 | 1/2 | 0136 16 21 | 13,7 | 22 | 41 | 20 | 11 | 0,041 |
| 13 | 3/4 | 0136 16 27 | 13,7 | 27 | 44 | 20 | 11 | 0,071 |

The 2 central digits in the product code part number represent the tube o.d.
 Ex : 0136 16 27
 This range of adaptors is limited to the maximum size (16 x 13) of Legris nylon tube.

0191 tailpiece adaptor for flexible tube, BSP parallel

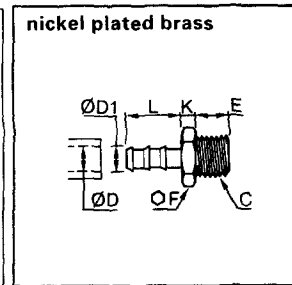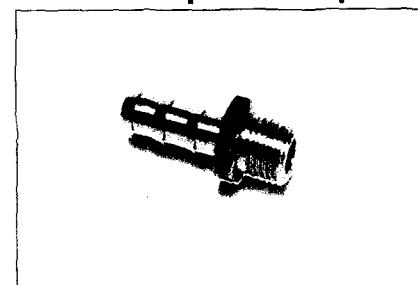

| ØD | C | | ØD1 | E | F | K | L | Δkg |
|----|-----|------------|------|-----|----|---|------|-------|
| 4 | 1/4 | 0191 04 13 | 6 | 9,5 | 17 | 5 | 22,5 | 0,019 |
| 7 | 1/4 | 0191 07 13 | 9 | 9,5 | 17 | 5 | 22,5 | 0,021 |
| 7 | 1/2 | 0191 07 21 | 9 | 11 | 27 | 7 | 29,5 | 0,065 |
| 10 | 1/4 | 0191 10 13 | 12,2 | 9,5 | 17 | 5 | 22,5 | 0,021 |
| 10 | 1/2 | 0191 10 21 | 12,2 | 11 | 27 | 7 | 29,5 | 0,060 |
| 13 | 1/4 | 0191 13 13 | 15,2 | 9,5 | 17 | 5 | 22,5 | 0,023 |
| 13 | 1/2 | 0191 13 21 | 15,2 | 11 | 27 | 7 | 29,5 | 0,058 |
| 16 | 1/2 | 0191 16 21 | 18,5 | 11 | 27 | 7 | 36,5 | 0,069 |