


EBM7LR403 Datasheet

Technical Specifications

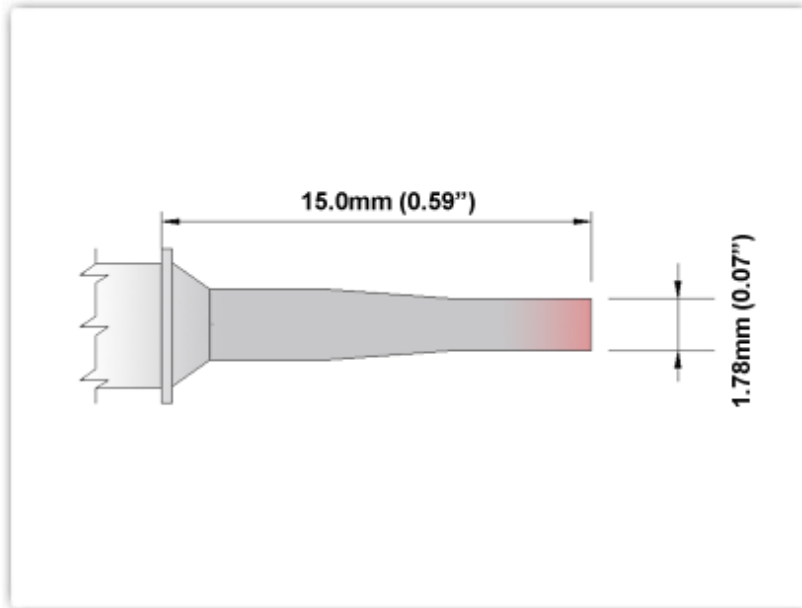


EBM7LR403

Chisel 60° Long Reach 1.78mm (0.07")

Tip Style: Chisel 60°
 Tip Width: 1.78mm (0.07")
 Tip Length: 15.00mm (0.59")

| | |
|--|--|
| 700 Type Cartridge ¹ : | 350°C - 398°C |
| RoHS Compliant ² / Lead Free: | YES |
| Equivalent to: | STTC-142 |
| For Use With: | EB-9000S-1, EB-9000S-2, MX500 and MX5000 |

Material Composition

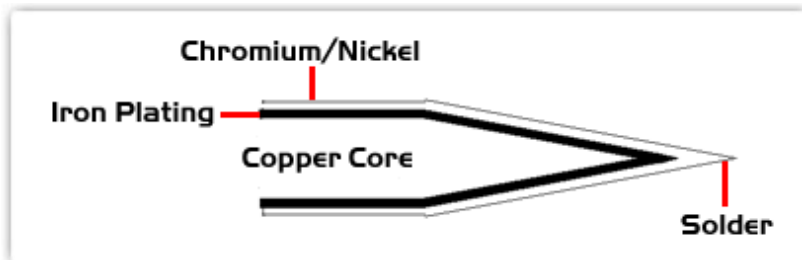

**All components
 are RoHS
 compliant and
 Lead-Free.**

¹ Easy Braid Co. tip cartridges will typically idle within a temperature range of +/-1.1°C. However, there is variation in idle temperature across tip geometries within an individual temperature series. Easy Braid Co. offers a wide variety of tip geometries from 0.25mm fine point tip to 5mm chisel. The length and geometry of a tip will have an influence on the tip idle temperature. To accurately measure idle temperature it will depend greatly on the measurement method, technique and equipment used. Two different methods or the use of alternative equipment will produce different test results.

² Please refer to <http://www.rohs.gov.uk> for details on RoHS Compliance.