




TLS 2200®/TLS PC Link™ Labels

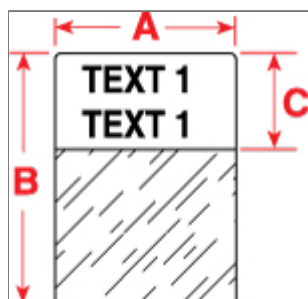

Labels for the TLS 2200® & TLS PC Link™ Thermal Transfer Portable Printers. Please Note: This material is UL recognised with its respective ribbon. See the "Recommended Ribbon Series" for the appropriate ribbon to use.

Specifications

Article Number:	018579
Order Reference:	PTL-31-427-GR
Size - Width (mm):	25.4
Size - Height (mm):	38.1
Finish:	Matt
Colour:	Green/Transparent
Printable Area - Width (mm):	25.4
Printable Area - Height (mm):	12.7
Material Type:	Self-Laminating Vinyl
Brady Material Number:	B-427
Adhesive:	Acrylic
Approval/Compliance:	UL Recognised
Max. Service Temp. °C:	70
Special Properties:	Excellent abrasion and smudge resistance, Excellent water & oil resistance, Self-Extinguishing, Self-Laminating
QTY. per Row:	1
Max. Lines of Text:	5
Max. Characters per Line:	24
Printer Compatibility:	TLS2200, TLSPCLink
Voice/Data Application:	Communications Cables
Wire Gauge:	10 to 4
Industry:	Data Communications, Electrical
Application(s):	Communications Cables, Panel Identification, Voice/Data Identification, Wire & Cable Marking

For further information on this product or for details of a local Brady Authorised Distributor, please use the "Contact Us" button