




Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshows
- Support

United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > _____

3M™ Highland™ Vinyl Insulated Female Disconnect Terminal FDV10-250Q, AWG 12-10, 25/bag

3M ID 80611602659 UPC# 00051128600047 3M Product Number FDV10-250Q

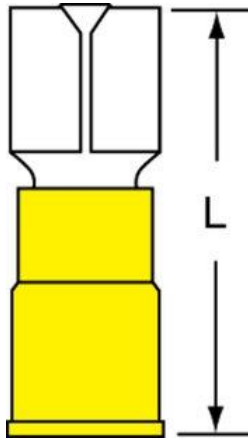

This female disconnect accepts a wire range of 12-10 AWG, a stud size of .187 and has a case quantity of 10 bags.

- Overview
- Documentation

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.128 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	12 - 10 AWG
CSA File Number	LR22190
Fastener Orientation	Female
Insulation Material	Vinyl
Length (L)	0.95 Inch
Mates with Male Tab Width (W)	0.25 Inch
Maximum Insulation Outer Diameter	0.25 Inch
Packaging	25 per bag
Pad Width	0.25 Inch
Terminal Style	Standard
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512