



Datasheet

Fibre Optic Cable Assembly

RS Stock number 536-8604

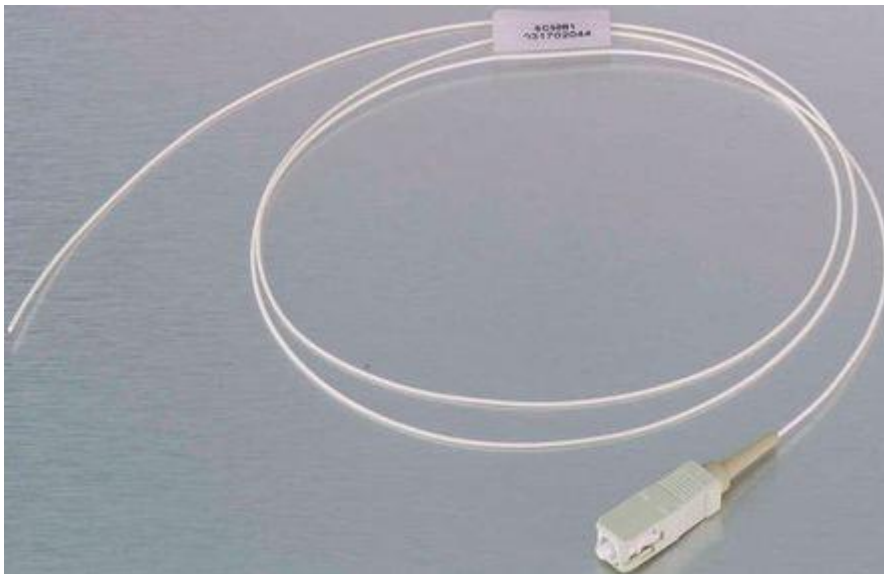

Dimensions (mm)

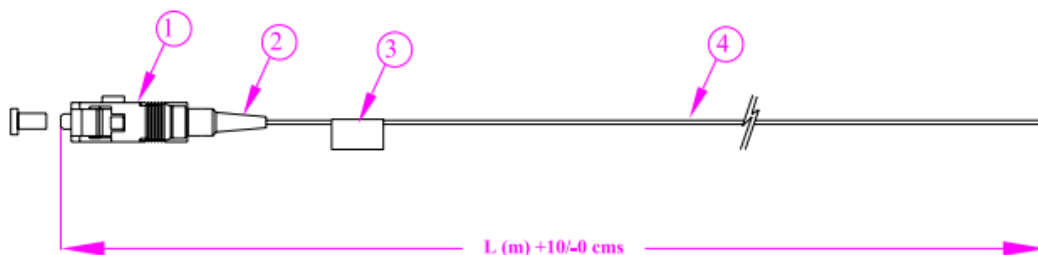

No.	Description	QTY
1	SC Connector	1
2	SC 900mm Boot	1
3	Identification Label	1
4	900mm Tight buffered fibre (Lm)	1

Optical Performance

Multimode :(@ 1300nm)
 Max IL : 0.30dB Typical: 0.20dB
 Singlemode: (@1310nm and/or 1550nm)
 E-2000: Max. IL-0.30dB
 Typical: 0.20dB
 Return Loss: >50dB
 RoHS Compliant
 Coiling Diameter: Coiling Diameter of the Patchcord shall be greater than 200mm