

HC-M-PN3-4,00-BU-V - Pneumatic contact



1663569

<https://www.phoenixcontact.com/gb/products/1663569>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Pneumatic socket with valve, for HC-M-PN3 module, internal hose diameter of 4.0 mm

Commercial data

Item number	1663569
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AF7ACZ
Product key	AF7ACZ
Catalog page	Page 593 (C-2-2019)
GTIN	4017918123376
Weight per piece (including packing)	1.03 g
Weight per piece (excluding packing)	0.87 g
Customs tariff number	39174000
Country of origin	CN

HC-M-PN3-4,00-BU-V - Pneumatic contact



1663569

<https://www.phoenixcontact.com/gb/products/1663569>

Technical data

Product properties

 
Product type	Pneumatic contact
Series	HC-M-03-PN
Type	Individual female contact
Integrated valve	Yes

Connection data

Connection technology

Connection technology	Hose connection
-----------------------	-----------------

Dimensions

Dimensional drawing	
Width	8.2 mm
Height	8.2 mm
Depth	23 mm
Diameter	4 mm

Mechanical characteristics

Internal diameter of pressure hose connection	4 mm
Contact diameter	5.2 mm

Material specifications

Material Valve	Polypropylene
Seal material	Buna-N
Contact material	Delrin acetal

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

Characteristics

Operating pressure	8.00 bar
--------------------	----------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 80 °C
---------------------------------	------------------

HC-M-PN3-4,00-BU-V - Pneumatic contact


1663569

<https://www.phoenixcontact.com/gb/products/1663569>



Drawings

Dimensional drawing

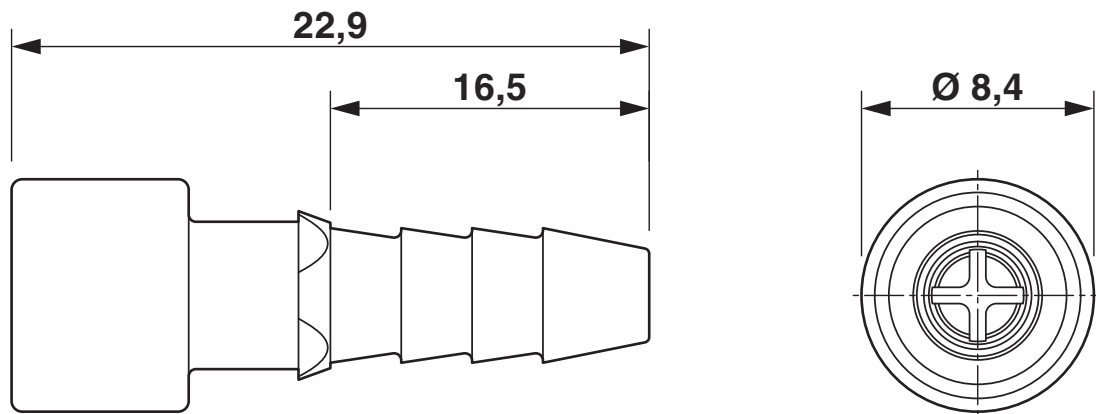

HC-M-PN3-4,00-BU-V - Pneumatic contact



1663569

<https://www.phoenixcontact.com/gb/products/1663569>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/1663569>



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-M-PN3-4,00-BU-V - Pneumatic contact



1663569

<https://www.phoenixcontact.com/gb/products/1663569>

Classifications

ECLASS

ECLASS-13.0	27440204
-------------	----------

ETIM

ETIM 9.0	EC000796
----------	----------

UNSPSC

UNSPSC 21.0	39121500
-------------	----------

HC-M-PN3-4,00-BU-V - Pneumatic contact



1663569

<https://www.phoenixcontact.com/gb/products/1663569>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk