


5380506



Pipe Cleaning Brush f/handle, 140 mm, Hard, Yellow

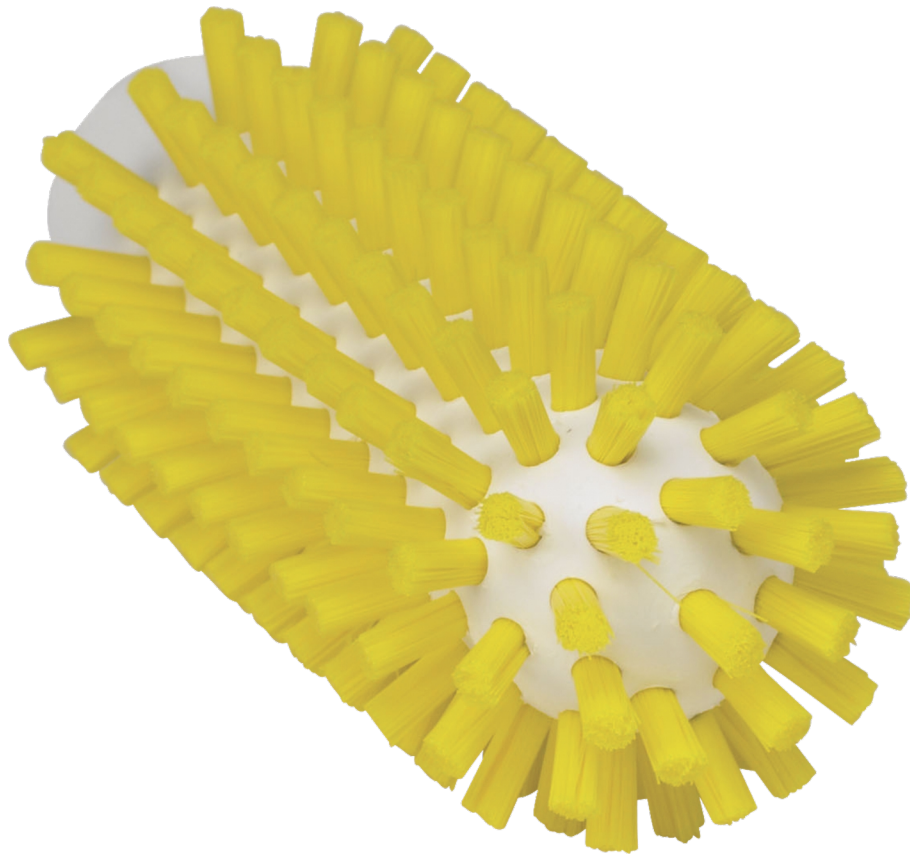

Fits all Vikan-handles. Tube cleaner is effective for cleaning of various kinds of tubes. Suitable for cleaning of e.g. sorting machines in the fishing industry or meat mincers in a butchery shop.

Technical Data

Item Number	5380506
Visible bristle length	10 mm
Material	Polypropylene Polyester Stainless Steel
Suitable for Food Contact (EU 1935/2004), DoC ¹	Yes
Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice	Yes
FDA compliant raw material (CFR 21)	Yes
Meets the REACH Regulation (EC) No. 1907/2006	Yes
Use of Phthalates (e.g. Bisphenol A)	No
Is Halal compliant	Yes
Box Quantity	15 Pcs.
Quantity per Pallet (80 x 120 x 200 cm)	2400 Pcs
Quantity Per Layer (Pallet)	240 Pcs.
Box Length	295 mm
Box Width	190 mm
Box Height	175 mm
Product Diameter	50 mm
Length	140 mm
Width	50 mm
Gross Weight	0,117 kg
Net Weight	0,106 kg
Cubik metre	0,0004 M3
Recommended sterilisation temperature (Autoclave)	121 °C
Max. cleaning temperature (Dishwasher)	93 °C
Max usage temperature (food contact)	80 °C
Max usage temperature (non food contact)	100 °C
Min. usage temperature	-20 °C
Min. pH-value in usage concentration	2 pH
Max. pH-value in Usage Concentration	10,5 pH
Gtin-13 Number	5705025380650
GTIN-14 Number (Box quantity)	15705025380657
Commodity Code	96039099
Country of origin	Denmark

New equipment should be cleaned, disinfected, sterilised and any labels removed, as appropriate to its intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.