

Plastic wall distributor

Input M32 on the top, RCB/circuit breaker

Item-no.: 0530x0200000



Robust and shockproof cover made of high-quality ABS plastic

Easy wall installation

Protective switchgear below lockable, shockproof cover made of polycarbonate

Sockets with self-closing hinge lids made of shockproof polyamide 6

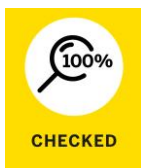
Features: sockets with hinge lids 4 x 16A/230V, 1 x 16A/400V, 1 x 32A/400V

Safety (ABB): 2 x circuit breaker 3 pole, 2 x circuit breaker 1 pole, RCB 40A/400V type A 30mA

Input via cable gland PG M32 from the top (blind gland M32 on the bottom)

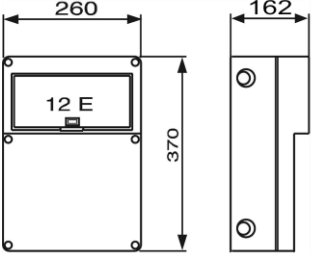

Made in Germany, 100% checked, with serial number, testing protocols available

Protection class: IP 54



Plastic wall distributor

Technical data

<p>Output:</p> <p>1 x CEE 32 A, 400 V~</p> <p>1 x CEE 16 A, 400 V~</p> <p>4 x socket (type E) 230 V~</p>	<p>Safety:</p> <p>1 x circuit breaker 32 A, 3-pole, C</p> <p>1 x circuit breaker 16 A, 3-pole, C</p> <p>2 x circuit breaker 16 A, 1-pole, C with RCB-switch 40 A, type A, 400 V~, 4-pole, 0,03 A via all outputs</p>	
<p>Input: Cable gland M32 on the top (blind gland M32 on the bottom)</p> <p>Weight: 4,715 kg</p> <p>Protection class: IP54</p> <p>Protection degree: II</p> <p>Customized versions on request.</p>		
<p>Item-no. 0530x0200000 EAN 4012096010456 PU 1</p>		<p>370 x 260 x 162 mm Dimensions (L x W x H)</p>