


Datasheet

Yellow Insulated Crimp Receptacle

RS Stock number [534-531](#)

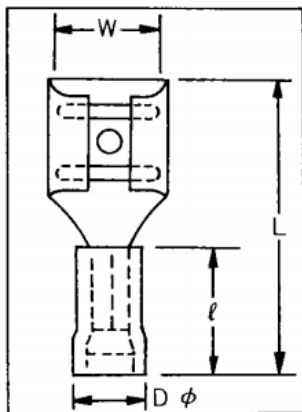

Wire Range

Dimensions

Tab Size

Stock no.	Insulation Colour	AWG	mm ²	W	Dφ	L	ℓ	AWG	mm
2082442	Red	22-16	0.5-1.5	4.0	4.3	19.0	9.8	.110x.020	2.8x0.5
534345	Red	22-16	0.5-1.5	4.0	4.3	19.0	9.8	.110x.020	2.8x0.8
534389	Red	22-16	0.5-1.5	5.8	4.3	19.0	9.8	.187x.020	4.8x0.5
534395	Red	22-16	0.5-1.5	5.8	4.3	19.0	9.8	.187x.020	4.8x0.8
534339	Red	22-16	0.5-1.5	7.6	4.3	20.5	9.8	.250x.032	6.3x0.8
534733	Blue	16-14	1.5-2.5	5.8	4.9	19.0	9.8	.187x.020	4.8x0.5
534749	Blue	16-14	1.5-2.5	5.8	4.9	19.0	9.8	.187x.032	4.8x0.8
534698	Blue	16-14	1.5-2.5	7.6	4.9	20.5	10.0	.250x.032	6.3x0.8
534531	Yellow	12-10	2.5-6.0	7.6	6.6	24.6	13.7	.250x.032	6.3x0.8