



SPECIFICATION

- Strong pressure die-cast LM2 aluminium body. Textured black, full polyester powder finish as standard
- White option finish
- Hinged clear prismatic (or satin option on LED versions), flame-retardant polycarbonate cover
- Tamper-resistant cover screws as standard
- Optional photocell control
- Bezel for semi-recessed mounting
- Complies with M.O.D. JSP482 Chapter 8 Document for 'Category C' areas
- Fitted with 3500K lamp or 4000K LEDs



Bezel for semi-recessed mounting - black



LED version - Clear cover



LED version - Satin cover

LED CHARACTERISTICS

Ra	°K	L70/B10	P/U	%	R/Rx	PF	LL/CW
80	4000	50K	P	85	R	>0.95	77.9

For LED characteristics explanation see www.thorlux.com/led-characteristics

ACCESSORIES

DESCRIPTION	CAT. No.
Bezel for semi-recessed mounting (<i>black finish</i>)	PS 11876B
Bezel for semi-recessed mounting (<i>white finish</i>)	PS 11876W
Key for tamper-resistant screw kit	KY 7979

OPTIONS

DESCRIPTION	SUFFIX	EXAMPLE
Photocell ▲	PC	PS 8128PC

▲ Not available on LED or recessed versions

RANGE

	LAMP	CAT. No.	APPROX. kg
CLEAR COVER	16W LED	PS 14913L	2.8
	21W 2D	PS 8128J	3.2
	28W 2D	PS 7951J	3.2
	38W 2D	PS 7952J	3.2
SATIN COVER	16W LED	PS 14914L	2.8
RETRO-FIT GEAR TRAY	16W LED	PS 14917L	0.8

WHITE OPTION - add suffix **W** - White e.g. **PS 14913LW** etc.


CIRCUIT TYPE - **J** - non-dimming (HF fluorescent) / **L** - non-dimming (LED)

EMERGENCY VERSION - prefix catalogue number with:
ECT - Emergency / **TCT** - AutoTest e.g. **ECT 14538L** etc.
 Emergency and AutoTest versions add 0.7kg to weights listed




PHOTOMETRIC GUIDE

PASSLIGHT - LED VERSION - POLYCARBONATE COVER

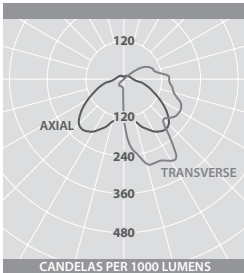


Luminaire Lumen Output
24W = 1520lm
38W = 2060lm

PASSLIGHT - LED VERSION - GLASS COVER

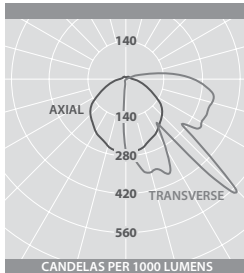


Luminaire Lumen Output
24W = 1650lm
38W = 2240lm

PRISMALETTE - LED VERSION - CLEAR COVER

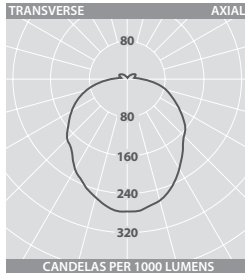


Luminaire Lumen Output
16W = 1480lm

PRISMALETTE - LED VERSION - SATIN COVER

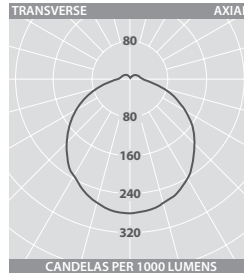


Luminaire Lumen Output
16W = 1400lm

PRISMALUX - LED VERSION - POLYCARBONATE COVER

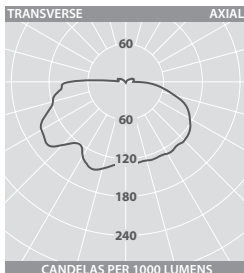

Luminaire Lumen Output
20W = 1600lm
32W = 2610lm

PRISMALUX - LED VERSION - GLASS COVER

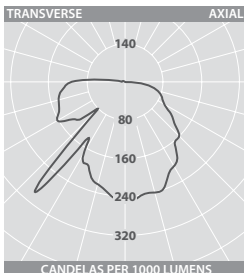


Luminaire Lumen Output
20W = 1720lm
32W = 2770lm




DIMENSIONS

Passlight

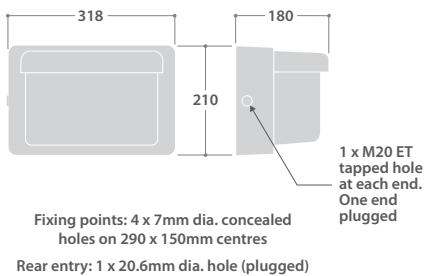

Prismalette

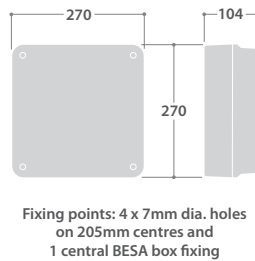

Prismalux

