



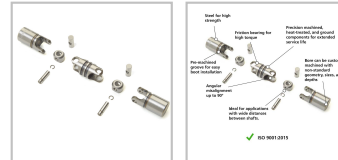

UD20-XX-XX-F-KIT

Ruland UD20-XX-XX-F-KIT, Machinable Bore Double Universal Joint Kit, Friction Bearing, Steel, 1.245" (31.6mm) OD, 5.625" (142.9mm) Length

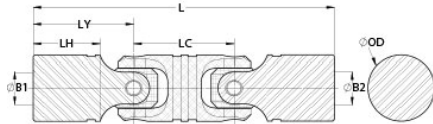

Description

Ruland UD20-XX-XX-F-KIT is a double cardan friction bearing universal joint kit that can be machined with a bore size and geometry of the user's choice. It has a 1.245" (31.6mm) OD and 5.625" (142.9mm) length. UD20-XX-XX-F-KIT is ideal for applications with wide distances between shafts and can accommodate all forms of misalignment. This plain bearing double universal joint is comprised of pins and blocks that are precision machined, selectively heat treated, and ground for high strength, accuracy, and wear resistance. The combination of these components with precision ground and hardened yoke ears allow for a longer lifespan, increased performance in demanding applications, and greater angular misalignment of up to 90° when compared to commodity style double universal joints. UD20-XX-XX-F-KIT is made from high grade alloy steel for durability and high strength. It can be combined with boot UBOOT20/32-NI-KIT to protect the joints from unwanted contaminants such as dust or water and self lubricate reducing maintenance time. This double cardan universal joint is manufactured in the USA by Belden Universal for strict control of processes.

Product Specifications

Bore (B1)	No Bore	Small Bore (B2)	No Bore
B1 Max Shaft Penetration	1.250 in (31.8 mm)	B2 Max Shaft Penetration	1.250 in (31.8 mm)
Joint Outer Diameter (OD)	1.245 in (31.6 mm)	Length (L)	5.625 in (142.9 mm)
Center Yoke Length (LC)	1.875 in (47.6 mm)	Yoke Length (LY)	1.875 in (47.6 mm)
Hub Depth (LH)	1.250 in (31.8 mm)	Max Round Bore (Inch)	0.750 in
Max Round Bore (Metric)	19 mm	Max Hex or Square Bore (Inch)	0.7500 in
Max Hex or Square Bore (Metric)	16 mm	Max Blind Bore (Inch)	1.0000 in
Max Blind Bore (Metric)	25 mm	Max Round Bore w/ Key (Inch)	3/4" Bore, 3/16" Keyway
Max Round Bore w/ Key (Metric)	19mm Bore, 6mm Keyway	Peak Torque	4700 in-lb (531.0 Nm)
Rated Torque	940 in-lb (106.2 Nm)	Max Operating Angle	90°
Material Specification	Alloy Steel	Manufacturer	Belden Universal
Country of Origin	USA	Weight (lbs)	1.545000
Recommended Lubricant	LUBRIPLATE No. 1200-2	Matching Boot Cover	UBOOT20/32-NI-KIT
UPC	634529288535	Tariff Code	8483.60.4000
UNSPC	25173810		

Note 1 Performance ratings are for guidance only. The user must determine suitability for a particular application.

Prop 65  **WARNING** This product can expose you to the chemical Ethylene Thiourea, known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.