




Technical data

51222

One direction thrust ball bearings

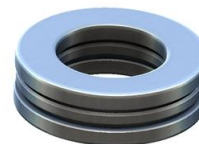

VISUAL (S)

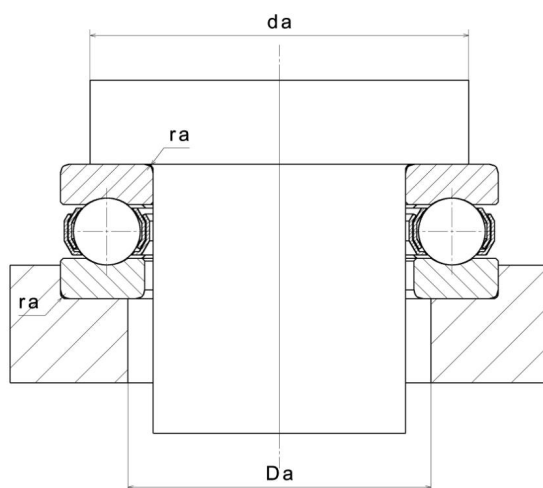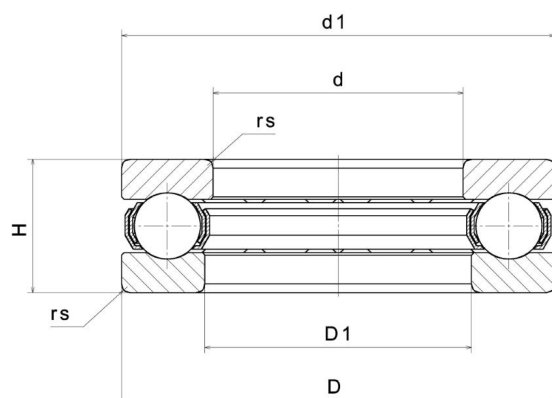

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	110 mm
D - External diameter	160 mm
T - Thrust bearing height	38 mm
rs - Min fillet radius	1,1 mm
Mass	2,46 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	153000000 mN
C0a - Static axial load rating	450000000 mN
Cua - Limit axial load rating	17500000 mN
N lim - Oil lubrication limit speed	10800 °/s
N lim - Grease lubrication limit speed	7200 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	130 mm
da min - Min shoulder diameter IR	140 mm

