


shock absorber DYEF-M6-Y1

Part number: 1179831

FESTO

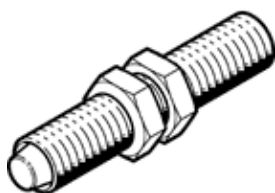

Data sheet

Feature	Value
Size	M6
Stroke	1.5 mm
Cushioning	P cushioning without metal fixed stop
Assembly position	Any
Position detection	No
Max. impact speed	0.8 m/s
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	0 ... 60 °C
Cushioning length	1.5 mm
Max. energy consumption per stroke	0.08 J
Product weight	6 g
Mounting type	with lock nut
Materials note	Free of copper and PTFE Conforms to RoHS
Material seals	NBR
Material housing	High alloy steel