

DPRO MITW 11 W/840 E27

OSRAM DULUX PRO MINI TWIST | Compact fluorescent integrated, spiral shape



Areas of application

- High-quality domestic and professional environments
- General illumination
- Wherever light is required quickly
- Outdoor use in enclosed and ventilated luminaires only

Product benefits

- Compact dimensions
- Higher luminous efficacy
- Great light color variation
- Extremely fast lumen ramp-up thanks to Quick Light Technology

Product features

- Quick Light: 60 % light output in <20 s (<30 s for 28 W product)
- Warm Comfort Light – energy-saving light similar to that of an incandescent lamp
- Available in 3 light colors: 825, 840 and 865
- Good quality of light; color rendering index $R_a : \geq 80$; constant chromaticity



Technical data


Electrical data

Nominal wattage	11 W
Nominal voltage	220...240 V
Rated wattage	11 W
Claimed equiv. conventional lamp power	55 W
Operating frequency	50...60 Hz
Nominal current	0.11 A
Energy consumption	11 kWh/1000h

Light technical data

Nominal luminous flux	660 lm
Color temperature	4000 K
Rated luminous flux	660 lm
Light color	840
Light color as per EN 12464-1	Cool White
Color rendering group	1B
Color rendering index Ra	≥80

Dimensions & weight

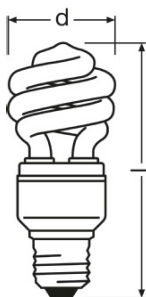

Product line drawing

Overall length	96.0 mm
Product weight	50.00 g

Colors & materials

Mercury-free	No
--------------	----


Product datasheet

Lamp mercury content	1.3 mg
----------------------	--------

Lifespan

Nominal lamp life time	10000 h
Number of switching cycles	30000
Rated lamp life time	10000 h

Additional product data

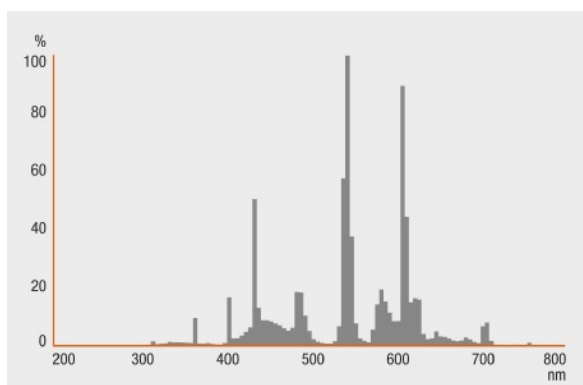

Spectral power distribution

Base (standard designation)	E27
Appropriate disposal acc. to WEEE	Yes

Capabilities

Dimmable	No
----------	----

Certificates & standards

Cleaning instruction in case of breakage	What to do if a lamp containing mercury breaks?
Energy efficiency class	A

Country specific categorizations

ILCOS	FB-11/40/1B-220/240-E27
-------	-------------------------

Product datasheet

Country specific information

Product code	METEL-Code	SEG number	STK-Number	UK Org
4008321986269	-	8331119	-	-

Product datasheet

Safety advice

In case of lamp breakage: www.osram.com/brokenlamp
Not for use with external dimmers or electronic switches.

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321986269	DPRO MITW 11 W/840 E27	Folding carton box 1	49 mm x 49 mm x 99 mm	0.24 dm ³	52.00 g
4008321987303	DPRO MITW 11 W/840 E27	Shipping carton box 10	113 mm x 105 mm x 254 mm	3.01 dm ³	611.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.
