


# C700 SAWHORSE / JOBSITE TABLE - 2 PACK

QUICK SETUP. STURDY. RELIABLE. SAFE.

45 x 95 mm & 95 x 95 mm SUPPORT ARMS

MATERIAL CUTTING BRACKETS

ADJUSTABLE HEIGHT LEGS

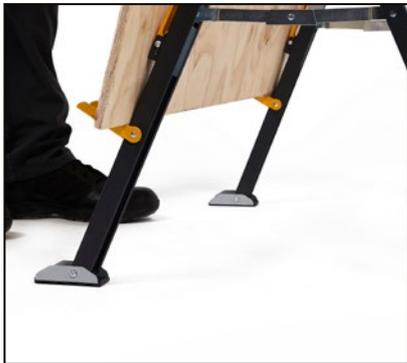

MATERIAL SUPPORT PEGS

PIVOTING FEET

EASILY FOLDS DOWN TO COMPACT SIZE

EASY CARRY HANDLE




**100%  
STEEL  
CONSTRUCTION**

**HEAVY-DUTY  
POWDER COATING  
AND ZINC PLATED  
SURFACES**


EASY TO SETUP SUPPORT ARMS THAT TRANSFORM TWO SAWHORSES INTO A SOLID JOBSITE TABLE, MAKING ONSITE JOBS QUICK AND EFFICIENT

**1 | OPEN**

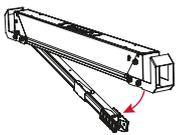


RELEASE LEGS FROM BODY STORAGE

**2 | LOCK**

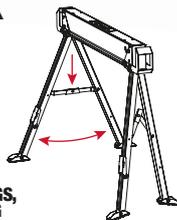

OPEN LEGS, LOCK LEG BRACES

**3 | PLACE TIMBER**

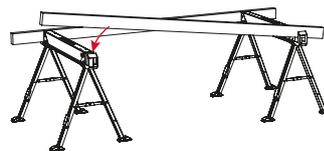

PLACE TIMBER IN SUPPORT ARMS

**4 | TABLE**



REST PLYWOOD ON TIMBER



\*All ToughBuilt products come with a two-year guarantee as standard, which can be extended to an impressive 25-years provided customers register their product within 30 days of purchasing