

# TC CLIP

## Current transformers



Split  
core

- Primary from 60 to 600 A
- Small size
- Built-in short-circuiting switch
- Reinforced hinge

### Choose your TC CLIP

	TCC 176	TCC 241	TCC 242	TCC 364	TCC 366
Primary	60 A	100 A	250 A	400 A	600 A
Secondary	1 A				
Power	0.2 VA	0.5 VA			
Accuracy class	3 %	1 %			
Diameter	17 mm	24 mm	24 mm	36 mm	36 mm
Size (mm)	64 x 33 x 34.4	74.5 x 45 x 34	74.5 x 45 x 34	91 x 57 x 40.5	91 x 57 x 40.5
Weight (g)	128	162	187	263	300


### General specifications

Highest network voltage	720 Vac
Dielectric test voltage	3 kV 50 Hz 1 min
Frequency	50 / 60 Hz
Operating temperature	-20 °C to +55 °C
Storage temperature	-30 °C to +90 °C


The TC CLIP models are compatible with all measurement products available on the market with input on a CT. In particular, they are ideal for use with the ENERIUM power monitors and ULYS submeters from ENERDIS®.




### Dimensions

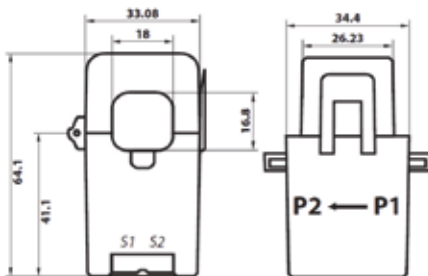

TCC 176

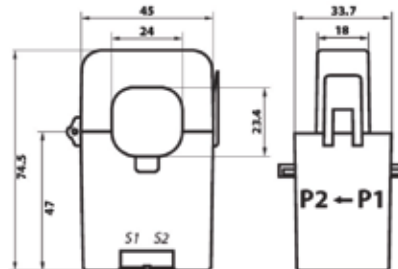

TCC 241 / 242

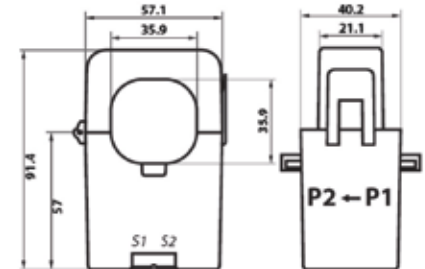

TCC 364 / 366

### To order

#### Individual TC CLIPS

Model	Primary	Reference
TCC 176	60 A	P01379609
TCC 241	100 A	P01379601
TCC 242	250 A	P01379602
TCC 364	400 A	P01379603
TCC 366	600 A	P01379604



#### Pack of 3 TC CLIP

Model	Primary	Reference
Pack of 3 x TCC 176	60 A	P01379610
Pack of 3 x TCC 241	100 A	P01379605
Pack of 3 x TCC 242	250 A	P01379606
Pack of 3 x TCC 364	400 A	P01379607
Pack of 3 x TCC 366	600 A	P01379608



**FRANCE**  
**Enerdis**  
 16, rue Georges Besse - Silic 44  
 92182 ANTONY Cedex  
 Tél : +33 1 75 60 10 30  
 Fax : +33 1 46 66 62 54  
 info@enerdis.fr  
 www.enerdis.fr

**UNITED KINGDOM**  
**Chauvin Arnoux Ltd**  
 Nelson Ct, Flagship Sq, Shaw Cross Business Pk  
 Dewsbury, West Yorkshire - WF12 7TH  
 Tel: +44 1924 460 494  
 Fax: +44 1924 455 328  
 info@chauvin-arnoux.co.uk  
 www.chauvin-arnoux.com

**MIDDLE EAST**  
**Chauvin Arnoux Middle East**  
 P.O. BOX 60-154  
 1241 2020 JAL EL DIB - LEBANON  
 Tel: +961 1 890 425  
 Fax: +961 1 890 424  
 camie@chauvin-arnoux.com  
 www.chauvin-arnoux.com