


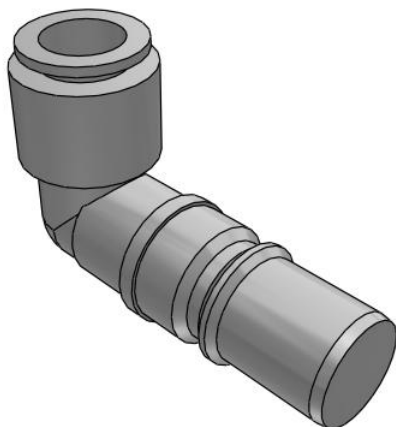

KK*P-*L, S-Couplers, Elbow Type with One-touch Fitting KK6P-12L

Datasheet


General series information

- Elbow Type with One-touch Fitting.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Tubing O.D.: ø3.2, ø4, ø6, ø8, ø10, ø12, ø16.

Standard specifications

Body Size	6 (1/2)
Applicable Tubing O.D.	Ø12 mm
Pressure medium	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Maximum ambient temperature	60 °C / 40 °C for Water
Minimum ambient temperature	-5 °C (with no freezing) / 5 °C for Water
Effective Area	82 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.040 Kg

Dimensions

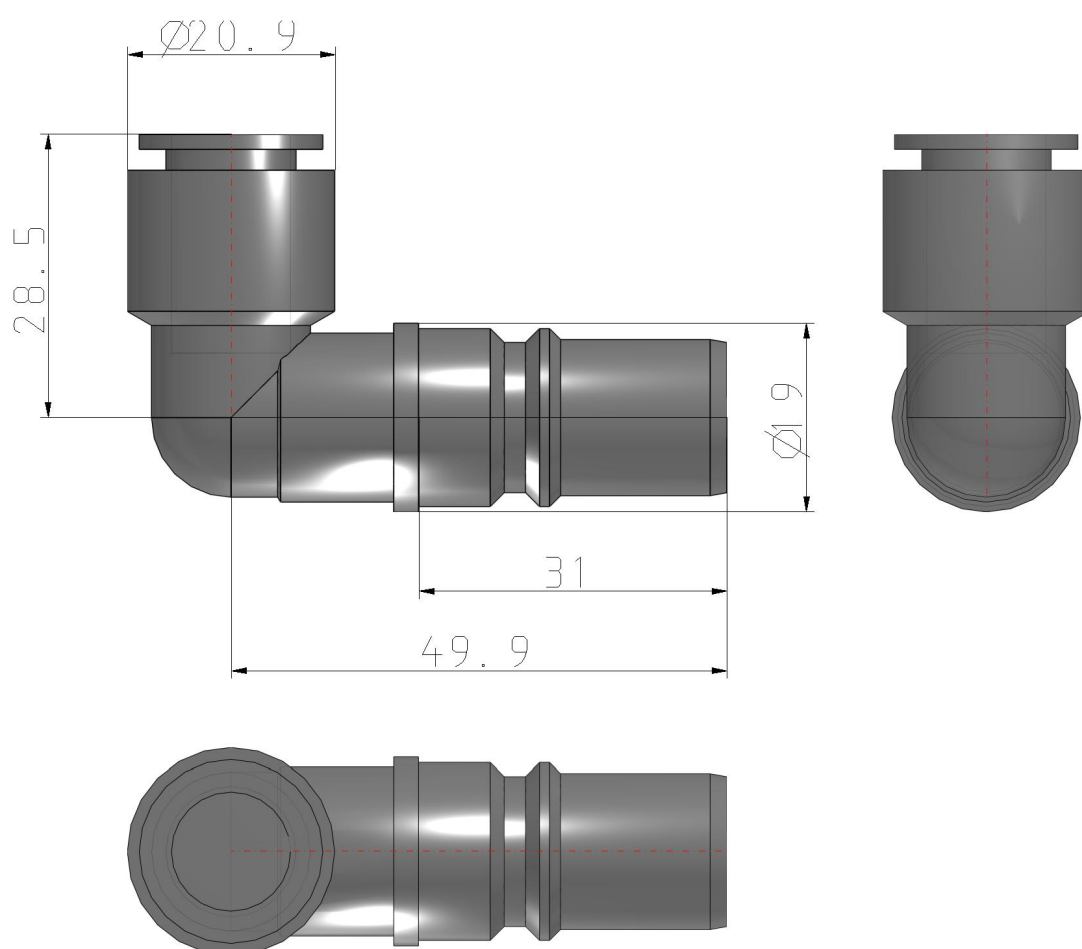

Additional information

Catalogue

[KK-C_EU.pdf](#)