



Brand of NTN Group

Technical data

MUCNFL205

Bearing units




Thermoplastic housing, stainless steel insert ball bearing with socket set screws, seal with slinger, food grease

KIT CONTENT

MUC205FD, NFL205

VISUAL (S)

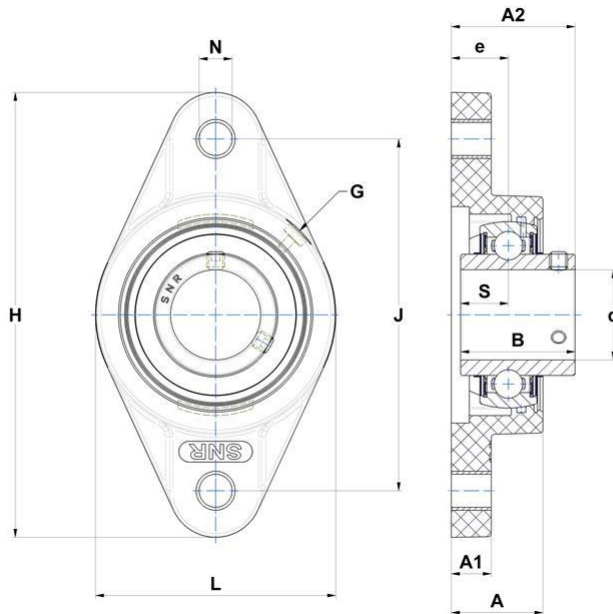

PRODUCT DEFINITION

Brand	SNR
A - Housing height	29,1 mm
A1 - Housing foot height / flange height	13,5 mm
A2 - Total height from mounting surface	36,8 mm
B - Width of Inner Ring	34,1 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Shaft diameter	25 mm
e - Distance mounting surface to bearing center	17 mm
G - Grease fitting	1/4"-28
H - Housing length, width or diameter	130 mm
J - Mounting holes distance	99 mm
L - Housing width / diameter	70 mm
N - Mounting hole dimension	11 mm
S - Distance front side/bearing centre	14,3 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	11900000 mN
C0 - Static load rating	6300000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,3 kg
Recommended tightening torque for set screw	3.9 N-m

