

Features

- Full Copper
- S/FTP
- LSZH
- Snagless
- 26AWG
- ANSI/TIA-568-C.2
- Gold Plated Contacts
- IEC 60332-1-2
- ISO/IEC 11801 ED.2
- CE
- UKCA
- ROHS
- REACH

RS PRO Black CAT 6A S/FTP LSZH Snagless Patch Lead 100% Copper

RS Stock No. 0834556



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Category 6A Ethernet cable, commonly referred to as Cat6A, is a cable standard for 10 Gigabit Ethernet. The cable standard provides performance of up to 600MHz and is suitable for 10BASE-T, 100BASE-TX (Fast Ethernet), 1000BASE-T / 1000BASE-TX (Gigabit Ethernet) and 10GBASE-T (10 Gigabit Ethernet). It is backwards compatible with previous standards such as Cat6, Cat5e and Cat5.

- **LSZH:** Low Smoke Zero Halogen cable reduces the amount of toxic and corrosive gas emitted during a fire.
- **Supports 10 Gigabit Ethernet / 10GBASE-T:** 10 Times faster than Gigabit Ethernet, 10GE (also called 10GbE or 10 GigE) supports a data rate of 10Gbits/s (billion bits per second).
- **S/FTP (or S/STP):** Screened and Foil (Shielded) Twisted Pair. Each individual pair is screened by foil and features an overall outer sheath. This shielding protects the cable from EMI (Electro-Magnetic Interference).
- **Snagless Connectors:** The connectors feature a *"bubble"* which protects the locking clip on the RJ45 from damage or being snapped off during transport or installation.
- **Flush Moulded Strain Relief:** The flush moulded design allows the patch cables to be installed side by side in high-density network switches. The strain relief allows the cables to move without damaging the cable or breaking away from the connector while it is plugged in a device.

General Specifications

Connector A	RJ45 Male
Connector B	RJ45 Male
Length	15cm up to 30mtr
Outer Sheath Material	LSZH
Sheath Colour	Black
Shielding	S/FTP


Approvals

Declarations	CE UKCA REACH ROHS ANS/TIA-568-C.2 IEC 60332-1-2 ISO/IEC 11801 ED.2
Standards Met	CE UKCA REACH ROHS ANS/TIA-568-C.2 IEC 60332-1-2 ISO/IEC 11801 ED.2

Similar Products

Stock No.	Length	Spec	Colour
0834535	15cm	CAT 6A S/FTP LSZH	Black
251-5152	25cm	CAT 6A S/FTP LSZH	Black
251-5158	0.5mtr	CAT 6A S/FTP LSZH	Black
251-5179	1mtr	CAT 6A S/FTP LSZH	Black
251-5170	1.5mtr	CAT 6A S/FTP LSZH	Black
251-5190	2mtr	CAT 6A S/FTP LSZH	Black
251-5202	3mtr	CAT 6A S/FTP LSZH	Black
251-5212	5mtr	CAT 6A S/FTP LSZH	Black
0834556	7mtr	CAT 6A S/FTP LSZH	Black
0834510	8mtr	CAT 6A S/FTP LSZH	Black
251-5224	10mtr	CAT 6A S/FTP LSZH	Black
251-5234	15mtr	CAT 6A S/FTP LSZH	Black
251-5244	20mtr	CAT 6A S/FTP LSZH	Black
251-5254	25mtr	CAT 6A S/FTP LSZH	Black
251-5257	30mtr	CAT 6A S/FTP LSZH	Black


Also available in our RS PRO range of CAT 6A cables are the colour options:
Grey, Orange, Green, Blue, Pink, Red, Violet, White and Yellow

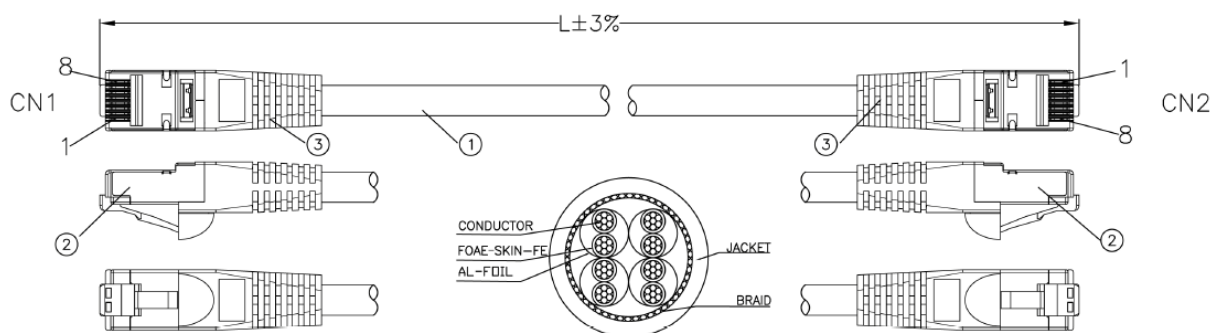

MATERIAL LIST:

NO.	PARTS NAME	SPECIFICATION DESCRIPTION
①	CABLE	SSTP (26AWG*1PR+A)*4+B+LSOH OD:5.8±0.2mm COLOR:Assorted upon request
②	RJ45 CONNECTOR	RJ45,8P8C,TWO FORK GOLD PLATED CONTACTS WITH METAL HOUSING
③	MOLDING PVC	MOLDING PVC 45P COLOR:Assorted upon request

Marking: SSTP CAT6A STRANDED 26AWG 4P LSOH PATCH ISOIEC 11801 AND ANSI/TIA-568-C.2

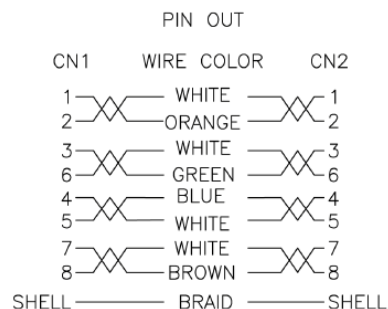

Working temperature:-20°C/+60°C

ELECTRONIC TEST:

A.OPEN/SHORT/INTERMITTENCE: 100%.

REMARK NO	CHA.NO	SIGNATURE	DATE	SIGN	W.T	SCALE	SSTP CAT6A 26AWG
DRAWN BY	Renzhi						
CHECKED BY							
AUDITED BY		APPROVED BY					