

RUN UP TO 15 METRES FROM ONE DRIVER

RGBXXK-48-100-20



19.2W/M



up to
850LM/M



IP20




Colour
Changing



15M Reel



100mm
Cut Points

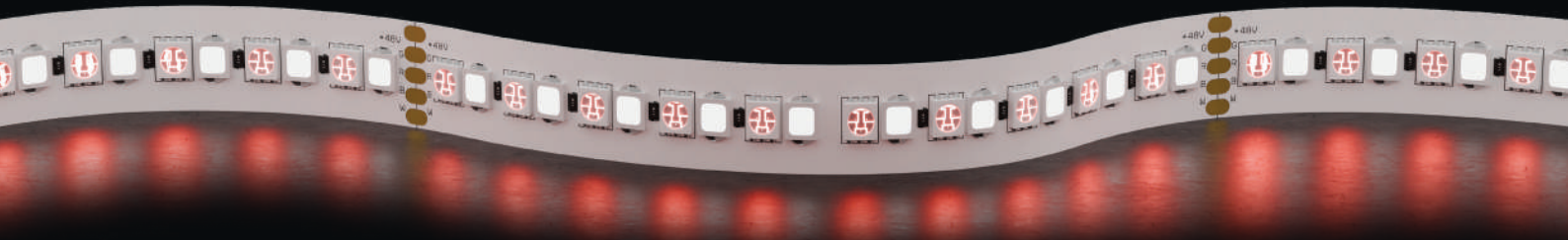

FEATURES

- Up to 15 metres of illumination, powered from one end or 30 metres powered from the middle
- Colour Changing RGB + Single Colour White
- Supplied on recyclable cardboard reels
- Industrial grade adhesive backing tape
- Working temperature -20°C - +40°C
- High efficacy
- 3 years warranty

SPECIFICATIONS

Stock Code	4797-951	5142-960	5303-944	4380-914
Part Code	RGB27K-48-100-20	RGB30K-48-100-20	RGB40K-48-100-20	RGB60K-48-100-20
Voltage	48VDC	48VDC	48VDC	48VDC
Power Consumption	19.2W/M	19.2W/M	19.2W/M	19.2W/M
Lumen Output	850LM/M	850LM/M	850LM/M	850LM/M
Tone (CCT)	RGB+2700K	RGB+3000K	RGB+4000K	RGB+6000K
LED/metre	100+100	100+100	100+100	100+100
Cut Points	100mm	100mm	100mm	100mm
IP Rating	20	20	20	20
Dimensions	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm



RGB

2700K

3000K

4000K

6000K

RUN UP TO 15 METRES FROM ONE DRIVER


RGBXXK-48-100-20



COMPATIBILITY



MECHANICAL DIAGRAM

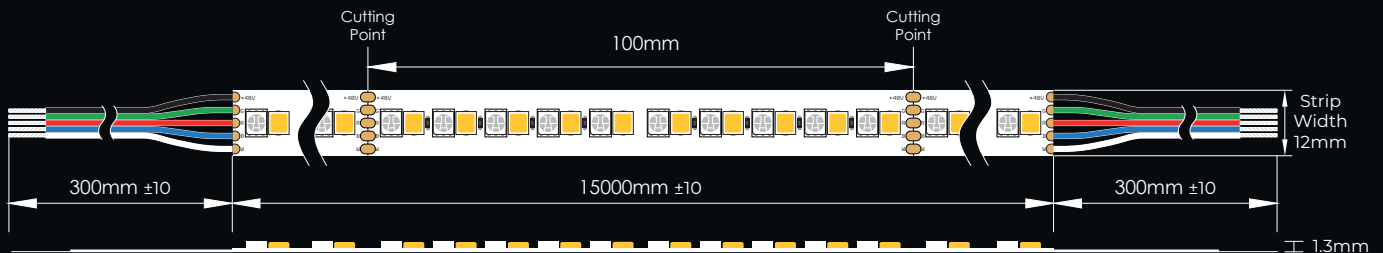

CONTROL METHODS (sold separately)

Remote Control
 Bluetooth (Apps, Voice Control)
 Sound Reactive (colour changing, dimming)
 Hard-wired wall-mounted controller
 RF wall-mounted or remote controlled

SUGGESTED DRIVERS

Up to 7 M

Power supplied from **ONE** end

HLG-150H-48A

Up to 15 M

Power supplied from **ONE** end

HLG-320H-48A


Up to 30 M

Power supplied from the **MIDDLE**

HLG-600H-48A

CONNECTORS (sold separately)


WIRE TO WIRE

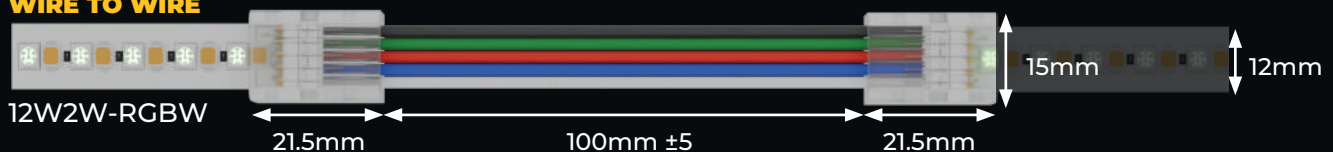

TAPE TO DRIVER



TAPE TO TAPE

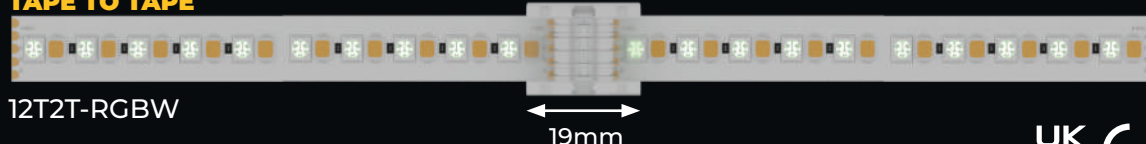

RUN UP TO 15 METRES FROM ONE DRIVER

RGBXXK-48-100-65



19.2W/M



up to
850LM/M



IP65




Colour
Changing



15M Reel



100mm
Cut Points

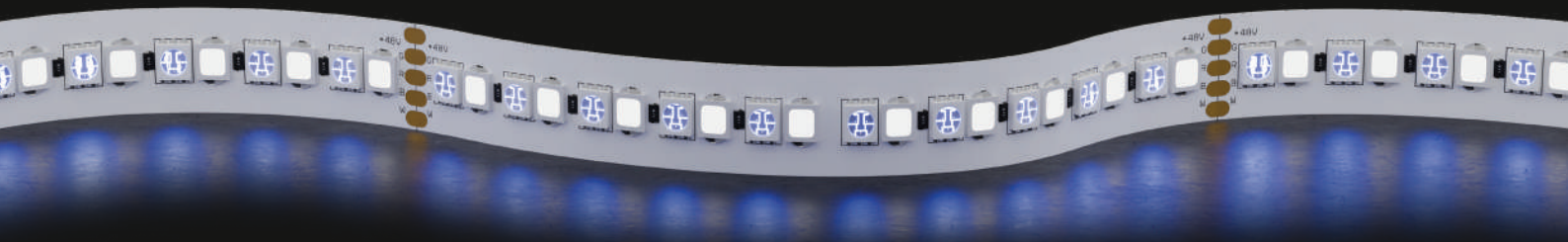

FEATURES

- Up to 15 metres of illumination, powered from one end or 30 metres powered from the middle
- Colour Changing RGB + Single Colour White
- Supplied on recyclable cardboard reels
- Industrial grade adhesive backing tape
- Working temperature -20°C - +40°C
- High efficacy
- 3 years warranty

SPECIFICATIONS

Stock Code	5150-920	4841-925	4467-952
Part Code	RGB30K-48-100-65	RGB40K-48-100-65	RGB60K-48-100-65
Voltage	48VDC	48VDC	48VDC
Power Consumption	19.2W/M	19.2W/M	19.2W/M
Lumen Output	765LM/M	765LM/M	765LM/M
Tone (CCT)	RGB+3000K	RGB+4000K	RGB+6000K
LED/metre	100+100	100+100	100+100
Cut Points	100mm	100mm	100mm
IP Rating	65	65	65
Dimensions	15000 x 12 x 3mm	15000 x 12 x 3mm	15000 x 12 x 3mm



RUN UP TO 15 METRES FROM ONE DRIVER


RGBXXK-48-100-65



COMPATIBILITY



MECHANICAL DIAGRAM

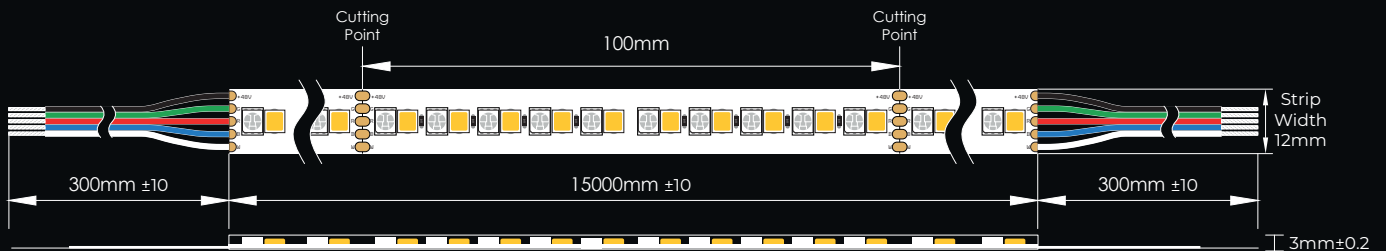

CONTROL METHODS (sold separately)

- Remote Control
- Bluetooth (Apps, Voice Control)
- Sound Reactive (colour changing, dimming)
- Hard-wired wall-mounted controller
- RF wall-mounted or remote controlled

SUGGESTED DRIVERS

Up to 7 M

Power supplied from **ONE** end

HLG-150H-48A

Up to 15 M

Power supplied from **ONE** end

HLG-320H-48A


Up to 30 M

Power supplied from the **MIDDLE**

HLG-600H-48A

CONNECTORS (sold separately)

WIRE TO WIRE

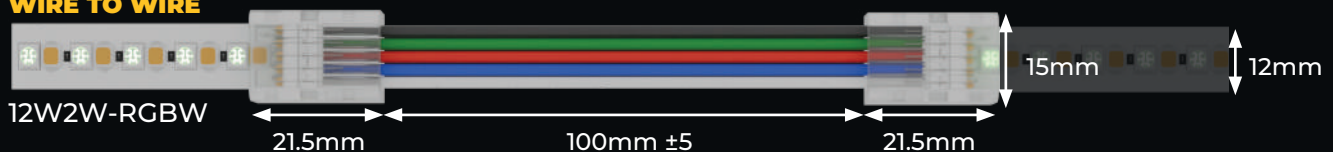

TAPE TO DRIVER



TAPE TO TAPE

