



ENGLISH


Datasheet
Stock No. 170-4259
RS PRO LED Floodlight



SPECIFICATIONS	
Watt	10W
Work Voltage	AC85-265V
Configuration Size	L114.3*W88.8*H85.7mm
Light Color	warm white
Color Temperature	3000-3500K
LED Angle	120°
Led Luminous Efficiency	≥80-90 lm/w
Led Flux	≥800-900lm
Lamp's Efficiency (%)	> 90%
Life Span	50000H
Protection Degree	IP65


Certificate	CE & ROHS
-------------	-----------

Dimensions:

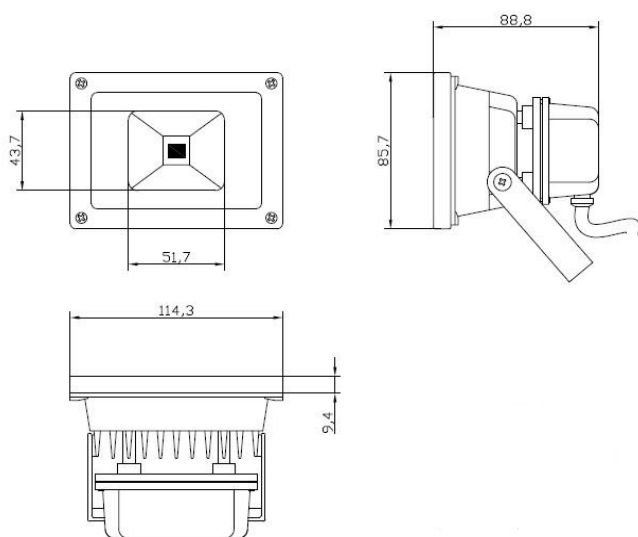


How to assemble:


Step 1:

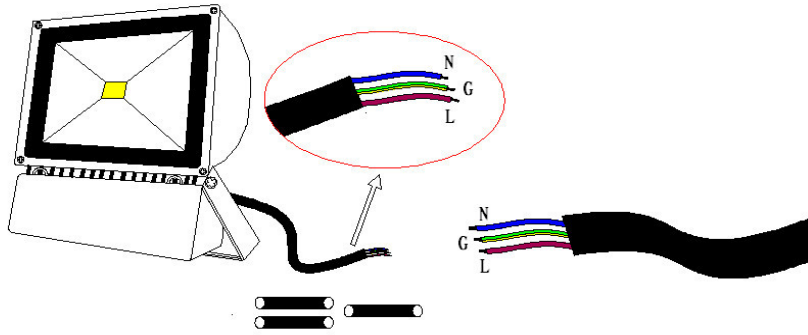

Step 2:

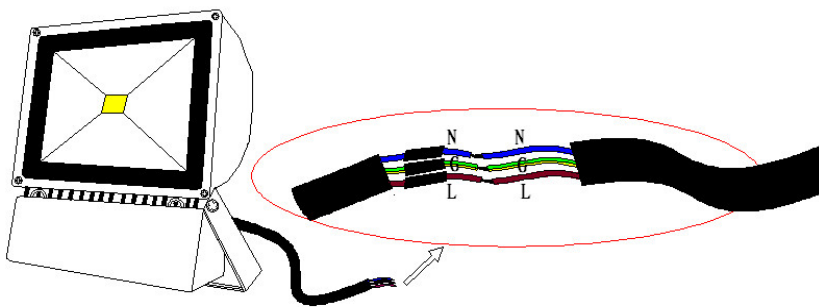

Step 3:

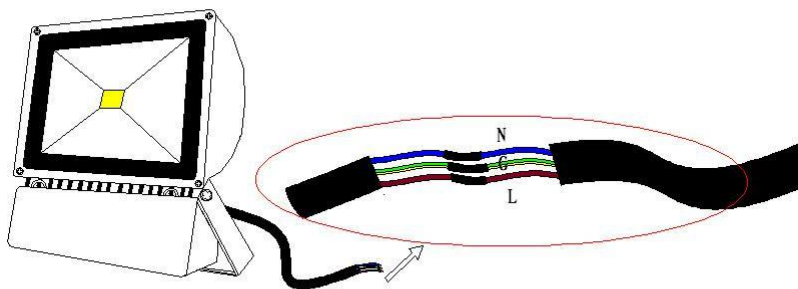

Feature:

Energy-saving Lighting.

Applications:

14/09/2017

Floodlights are for bars, clubs, hotels, plazas, commercial buildings facade, stages, squares, museums, art galleries, historical buildings, billboards, theatres, parks, gardens, etc.