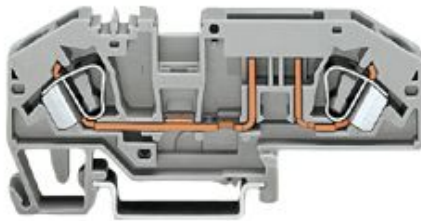

Item no.: 282-696
Product description: 2-CONDUCTOR FUSE TERMINAL BLOCK FORMINI-AUTOMOTIVE BLADE-TYPE FUSES WITH TESTING FACILITY WITHOUT BLOWN FUSE INDICATION



Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	1 (Rail Mounted Terminal Blocks)
Cross section [mm ²]	0.2 - 6 mm ²
Cross section [AWG]	24 - 10 AWG
Connection method	CAGE CLAMP® CONNECTION
Measured voltage EN	400 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	25 A
Current intensity EN	30 A
Weight	17.22 g
Color	gray
Wiring type	Angled Type
No. of connection Points	2
No. of potentials	2
Height	33.5 mm
Height	1.32 in
Width	8 mm
Width	0.315 in

Depth	85 mm
Depth	3.35 in
Strip length from	12 mm
Strip length to	13 mm



Strip length

0.49 in

Safety information 1

Nominal voltage and nominal current are defined by the fuse.

Safety information 2

Blade-type fuses, please note touchproof protection from 42 V

Mounting

TS 35



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
282-696	CSA	154112-1505033	24	30	24-10
282-696	UR	E45172	600	30	24-10

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected