

307BM.25 | 307BM - MAGNETIC TRAPEZOIDAL LEVELS




Norm :


DIN 877

Description :

- In reverse position, accuracy 0.75 mm/m.
- Massive light alloy body, pressure moulded.
- Electrostatic powder protective coating.

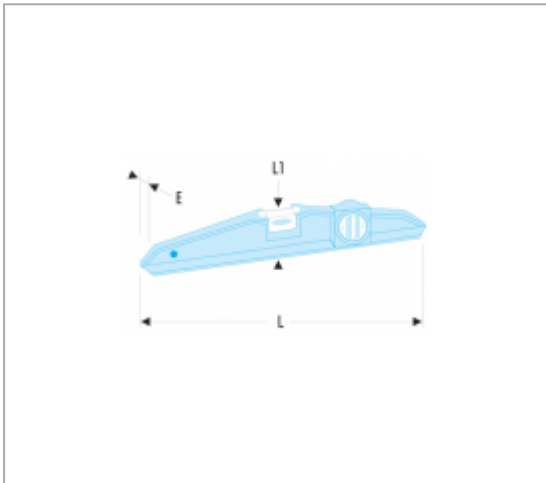

Informations :

	307BM.25
E [mm]	22
L [mm]	250
L1 [mm]	45
[g]	200