



Model No. M175EURDLH

56mm wide Excell® zinc body padlock with 51mm long shackle; set-your-own combination

Best Used For:



Self-Storage Units & Lockers

 


Sheds, Workshops & Garages



Trailers, Vans & Moving Trucks

Security Level:



High to maximum security:

Recommended for all use including industrial applications

Overview & Features

Product Features


- Tough-Cut? octagonal boron-carbide shackle is 50% harder than hardened steel
- 51mm shackle length for more uses
- 56mm wide zinc body with reinforced body bumper for scratch resistance
- Roller pin locking for maximum pick and pry resistance
- Shackle seal and hinged dial cover for superior weather resistance
- Set-your-own 4-digit combination for convenience and security; 10,000 possible combinations
- No reset tool required
- One directional dial feature for low light applications
- Limited Lifetime Warranty

Product Details

The Master Lock Excell® No. M175EURDLH Solid Body Padlock features a 56mm wide zinc body for strength and reliability. The 9mm diameter octagonal shackle is 51mm long and made of Tough-Cut™ boron-carbide, 50% harder than hardened steel, offering maximum resistance to cutting and sawing. The roller pin cylinder provides maximum pick and pry resistance. The hinged dial cover and shackle seal offers superior weather protection, and reinforced body bumper protects against scratches. The lock includes Set-Your-Own combination convenience, without the need for a reset tool. The Limited Lifetime Warranty provides peace of mind from a brand you can trust.

Product Specifications

Product Number	M175EURDLH
Body Width	56mm
Shackle Dimensions	A: 9 mm B: 51 mm C: 24 mm
Colour	Gold
Description	Not Keyed
Shelf Pack Qty	4
Master Carton Qty	24

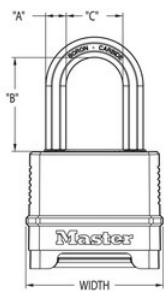

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France
O:+33-1-41437200 | F:+33-1-41437204
www.masterlock.eu