




ENGLISH

Datasheet

RS Pro 200cm Zinc Plated Steel Hydraulic Tubing, 2mm Wall Thickness, 345 bar, -40 to +120°C

RS Stock No: **400-7724**

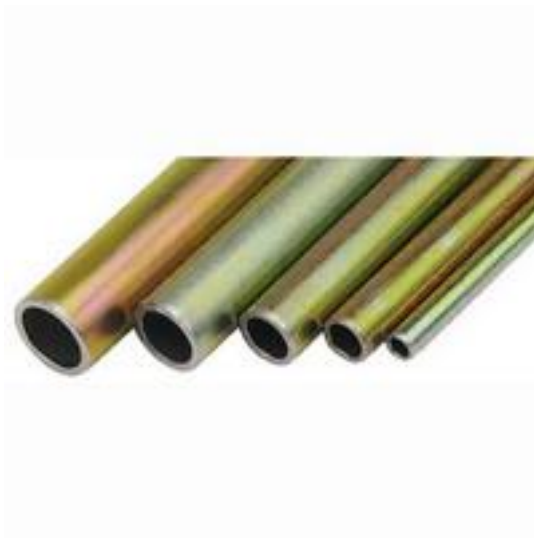

Product Details

RS Pro hydraulic tubing of 200 cm, has steel construction with zinc plated finish for durability and corrosion resistance. The tube has 2 mm wall thickness, 345 bar maximum operating pressure and -40 to +120°C operating temperature. It is compatible with range of EO hydraulic tube fittings, for fluid applications.

Features and Benefits

- Steel construction
- Comes in zinc plated finish
- Operating temperature range of -40 to +120°C

**Specifications:**

Finish	Zinc Plated
Length	200 cm
Material	Steel
Maximum Operating Pressure	345 bar
Maximum Operating Temperature	+120°C
Minimum Operating Temperature	-40°C
Outside Diameter	16 mm
Wall Thickness	2 mm
Weight	0.691 kg/m
Special Feature	Seamless Tube
Tensile Strength	340 N/mm ²
Yield Point	235 N/mm ²