
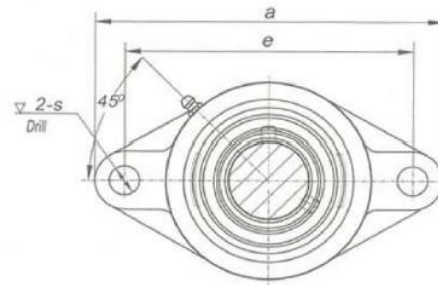


## 2 Bolt Flange Bearing unit – Metric

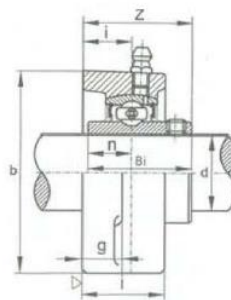

RS Article no.	Bearing unit No.	Shaft Dia.	Dimension (mm)										Bolt used	Bearing No.	Housing No.	Weight (kg)
		d (mm)	a	e	i	g	l	s	b	z	Bi	n	(mm)			
7508851	UCFL201	12	113	90	15	12	25.5	12	60	33.3	31.0	12.7	M10	UC 201	FL 201	0.49
7508860	UCFL202	15	113	90	15	12	25.5	12	60	33.3	31.0	12.7	M10	UC 202	FL 202	0.49
7508863	UCFL203	17	113	90	15	12	25.5	12	60	33.3	31.0	12.7	M10	UC 203	FL 203	0.49
7508867	UCFL204	20	113	90	15	12	25.5	12	60	33.3	31.0	12.7	M10	UC 204	FL 204	0.49
7508879	UCFL205	25	130	99	16	14	27.0	16	68	35.7	34.0	14.3	M14	UC 205	FL 205	0.63
7508873	UCFL206	30	148	117	18	14	31.0	16	80	40.2	38.1	15.9	M14	UC 206	FL 206	0.94
7508885	UCFL207	35	161	130	19	16	34.0	16	90	44.4	42.9	17.5	M14	UC 207	FL 207	1.2
7508898	UCFL208	40	175	144	21	16	36.0	16	100	51.2	49.2	19.0	M14	UC 208	FL 208	1.6
7508891	UCFL209	45	188	148	22	18	38.0	19	108	52.2	49.2	19.0	M16	UC 209	FL 209	1.9
7508895	UCFL210	50	197	157	22	18	40.0	19	115	54.6	51.6	19.0	M16	UC 210	FL 210	2.2
7508905	UCFL211	55	224	184	25	20	43.0	19	130	58.4	55.6	22.2	M16	UC 211	FL 211	3.2
7508908	UCFL212	60	250	202	29	20	48.0	23	140	68.7	65.1	25.4	M20	UC 212	FL 212	4.1