



EXPERT Adjustable wrenches



Description:

- ISO 6787
- DIN 3117
- ASME B 107.8 M
- Head tilted at 15° for a 30° deflection angle when flipped.
- Hardened chrome-vanadium steel body.
- Presentation: chromed, polished faces.
- Right-hand knob rotation.
- Registered model.
- Reduced nose thickness for better access.
- Round handle design for better ergonomics.
- Fully Tempered and hardened jaws.

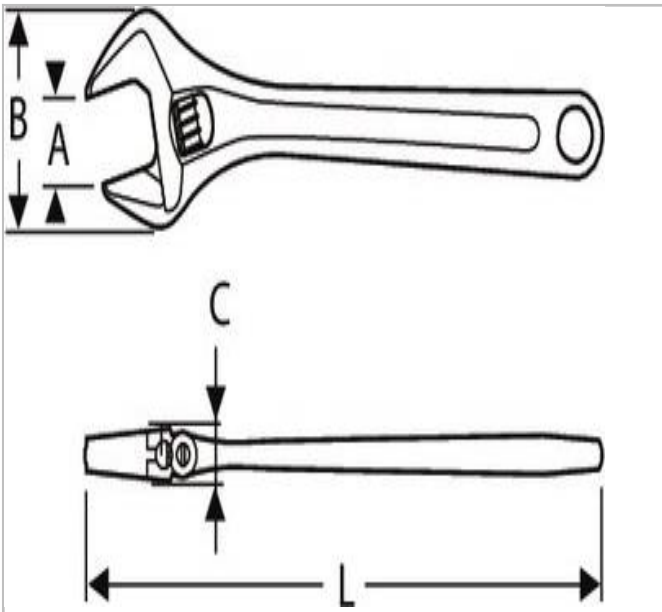

	A [mm]	Length L [mm]	Head Height C [mm]	Head Width B [mm]	Weight [Kg]
E117905	55.0	450.0	26	120.0	1,95
E117906	62.0	600.0	31	132.0	3,225
E187366	20.0	150.0	10,8	46.0	0,13
E187368	24.0	200.0	13,5	57.4	0,24
E187470	29.0	250.0	16	69.8	0,44
E187472	34.0	300.0	19	82.3	0,7
E187473	44.0	375.0	25	104.3	1,29