


Coupling hub EAMC-H-10-5-GB5-5

Part number: 8228646

FESTO

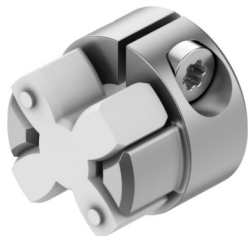

 [General operating condition](#)

Data sheet

Feature	Value
Mounting diameter 1	5 mm
Size	10
Nominal length	9.5 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	0.022 kgmm ²
Transmittable torque	0.6 Nm
Product weight	2 g
Note on materials	RoHS compliant