


**RASEY25-TV-VA**

Plummer block housing unit

Plummer block housing unit RASEY..-TV-VA,
RIBB plastic

Technical information

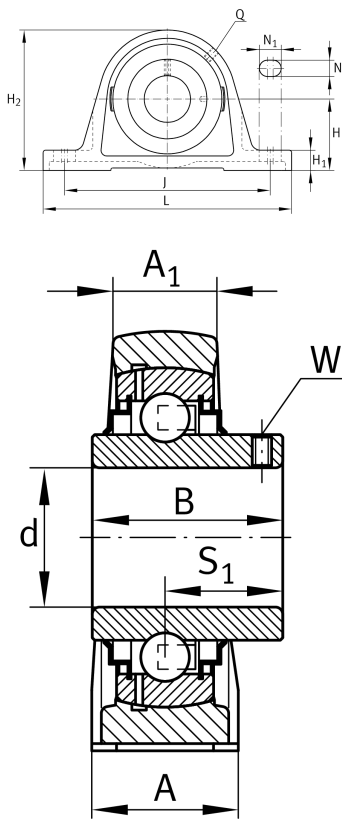

Your current product variant

Special material	TV	Plastic housing
Corrosion resistant bearing	VA	Corrosion-resistant VA design
Material	TV	Plastic

Main Dimensions & Performance Data

d	25 mm	Bore diameter
L	140.5 mm	Length
H 2	71 mm	Height
≈m	0.343 kg	Weight

Mounting dimensions

J	105 mm	Distance fixing bore
N	11 mm	Width (slot)
N 1	14 mm	Length (slot)

Dimensions

H	36.5 mm	Distance shaft axis
A	38 mm	Width (base)
H 1	14.5 mm	Height (base)
S	19.8 mm	Distance raceway
B	34.1 mm	Width
Q	1/4 - 28 UNF	Connection thread for lubrication



Additional information

GEH-ASE05-TV	Housing
GYE25-KRR-B-FA107-VA	Bearing designation
KASK05-S-G	End cap
KASK05-S-R-NBR	Open protecting cap

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	80 °C	Operating temperature max.