
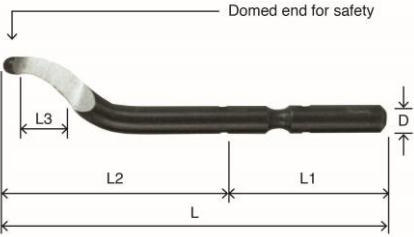


Deburring Blades

S101 Heavy Duty Deburring Blade

	RS Code	339-4803			
	Pack Reference	BK1010			
	Cutting	Right Hand			
	Works best on	Fine Edges on all materials			
	Used with Handle	NG-1, NG-3 + S Holder, Plastic Edge Off, Rapid Burr, Plastic Rapid Burr,			
	Packed Weight and Dimensions				
Code	Pack Quantity	Weight g	Wmm	Hmm	Lmm
S101 LH	10	40	65	8	83

	RS Code	339-4803
	Included Angle	40°
	Blade Material	HSS M2
	Blade Hardness	62 – 64 HRC
	L: Overall Length	44mm
	L1: Length Inside Handle	28mm
	L2: Protrusion from Handle Length	16mm
	L3: Cutting Length	7mm
D: Shank Diameter	3.2mm	