



Brand of NTN corporation

Technical data

USPFL207

Bearing units




Sheet metal housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US207G2, PFL207

VISUAL (S)

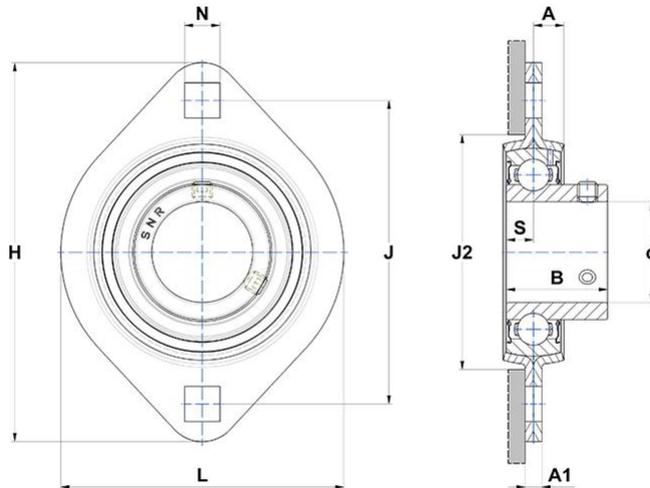

PRODUCT DEFINITION

Brand	SNR
A - Housing height	10,5 mm
A1 - Housing foot height / flange height	5 mm
A2 - Total height from mounting surface	26 mm
B - Width of Inner Ring	32 mm
d - Shaft diameter	35 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	2,5 mm
H - Housing length, width or diameter	123 mm
J - Mounting holes distance	100 mm
L - Housing width / diameter	93,7 mm
N - Mounting hole dimension	10,5 mm
S - Distance front side/bearing centre	8,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,63 kg
Recommended tightening torque for set screw	5.5 N-m

