


Blue Elastic Rubber Trolley Wheel 125mm, 200kg

Elastic Rubber-tyred wheel

PRODUCT

Article number 571-401-125L12

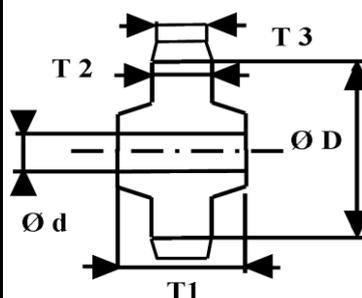

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, black bonded elastic rubber tyre.
 Hub : symmetrical with plain bore.

Specifications

Wheel Diameter - $\varnothing D \pm 1\%$	125 mm
Hub Type	Plain
Hub Length T1	44 mm ± 1
Width of Tread T2	36 mm ± 1
Width of Tread-on floor T3	36 mm ± 1
Axle Hole $\varnothing d$	$\varnothing 12$ mm
Hardness of tread A ± 4	A 70 Shore
Load capacity	200 Kg
Temperature	-20 / +60 °C
Weight	0,34 kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Quiet in use and high wear resistance.
 Reduces shock and vibration.
 Suitable for industrial floors and also interior floors