




1927E Reversible impact wrench, made from composite material

CE

Features:

- Double hammer impulse device
- Reverse control knob
- Three power adjustable screwing positions
- Exhaust through handle
- Vibration-damping handle

Free speed	7,000 rpm
Max. torque	750 Nm
Bolt capacity	Cl 8.8 M24 ● 36 mm
Bolt capacity	Cl 12.9 M20 ● 30 mm
Air inlet	1/4" GAS
Operating pressure	6.2 bar
Internal hose size (Ø)	10 mm
Mean air consumption	197 l/min
Weight	2.4 kg

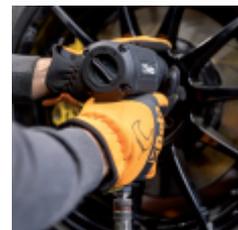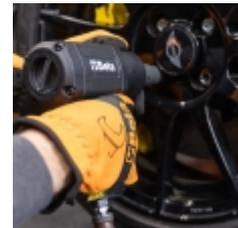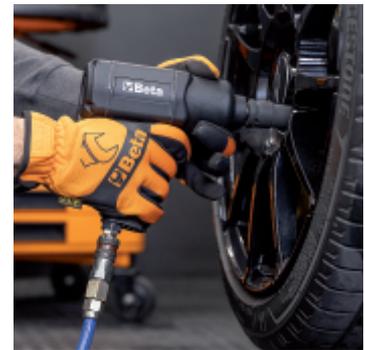

	art.	"	 kg
019270005	1927E	1/2	2,4