






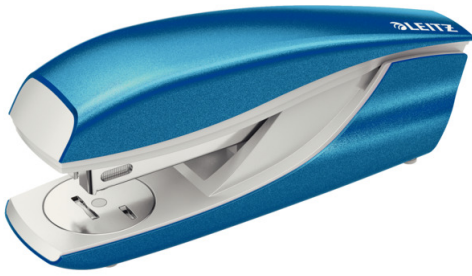


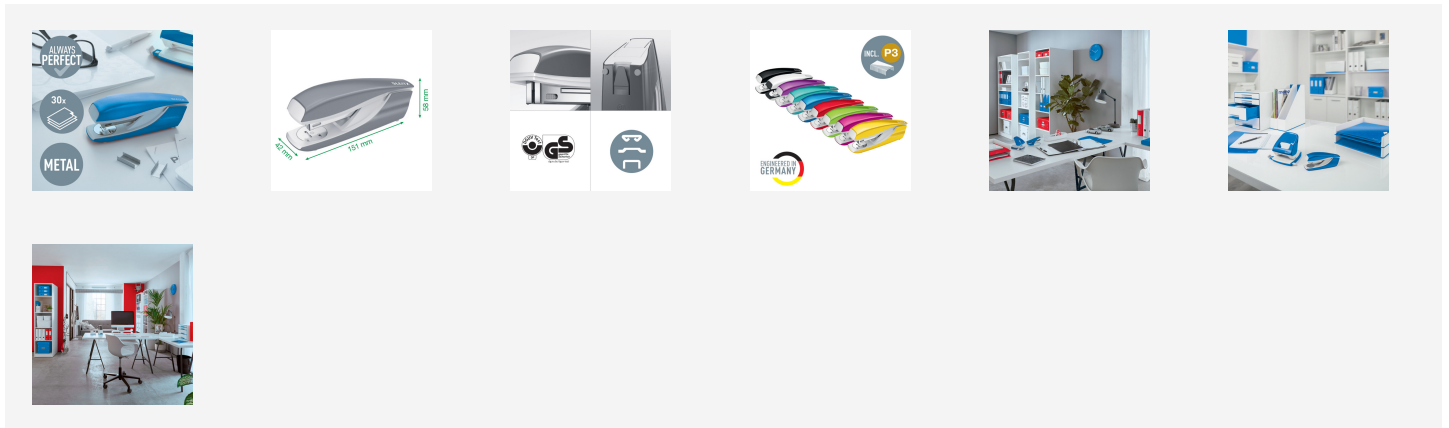


Leitz NeXXt WOW Metal Office Stapler

Metal stapler in striking WOW colours that let your personality shine through. For everyday use. Robust and reliable. Patented Direct Impact Technology and Leitz Power Performance staples P3 (24/6, 26/6) ensure perfect stapling every time.



Colour	Number	EAN code
 white	55021001	4002432395996
 yellow	55021016	4002432122998
 pink	55021023	4002432396009
 Red	55021026	4002432135257
 blue	55021036	4002432396016
 ice blue	55021051	4002432103126
 green	55021054	4002432123773
 purple	55021062	4002432103133
 black	55021095	4002432122172



Attributes

- Staples up to 30 sheets of paper (80 gsm)
- Effortless, accurate stapling with patented Direct Impact Technology
- Push-button easy to turn anvil to switch between open and closed stapling, 180° opening enables nailing function
- Give your workplace or your home the WOW factor with this range of products in striking and stylish colours
- For Leitz Power Performance P3 staples, 24/6 and 26/6, staples pack included
- Handy, integrated staple remover
- 10 year guarantee when using Leitz staples and GS safety tested
- To use with Leitz Power Performance staples – always sharp edges due to ongoing quality checks – for perfect stapling



Specifications

Number	55021036
Colour	blue
Material	Metal housing with plastic parts, metal mechanical parts
Dimensions (W x H x D)	42 x 58 x 151 mm
Capacity of Stapling	3mm/30 sheets (80 gsm paper)
Integrated Staple Remover	Yes
Type of Staples	100x Leitz P3 (24/6) or 140x Leitz P3 (26/6)
Type of Stapling	Stapling, pinning, tacking
Insertion Depth	40mm
Loading Mechanism	Top loading, 180° opening
Scope of delivery	Includes 200 P3 24/6 staples
Convenient hole punch	5008
GS certificate	yes
Weight	271 g
Pallet quantity	1800
Minimum order quantity	1
EAN code	4002432396016