


405.12 Diagonal cutters

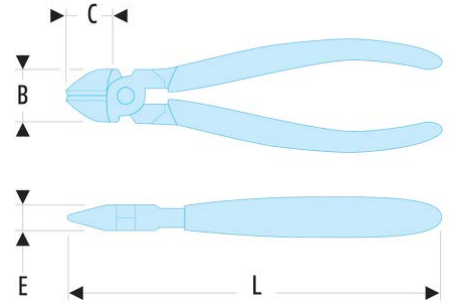

- 405: Axial cut.
- 416 - 435: Semi-flush cut, slim nose.
- 425: Flush cut, nose extended 13 mm.
- Finish: Matt burnished finish, red grips - return spring.

B [mm]: 16,0

C [mm]: 16,0

E [mm]: 16,0

L [mm]: 120

L1 [mm]: 8

[g]: 95