


NA2200-2RSR

Galet de roulement

Yoke type track rollers NA22...-2RSR, single row needle roller bearings with particularly thick-walled outer ring, needle roller and cage assembly and an inner ring, without axial guidance of the outer ring, lip seal radial sealing action on both sides, inner ring can be mounted separately

Information technique

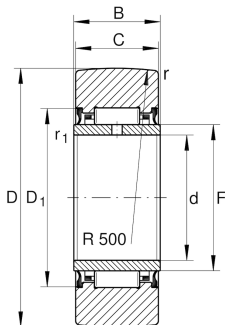

Votre alternative produit actuelle

joint	2RSR	Joint frottant des deux côtés
profile bague extérieure	R500	Diamètre extérieur sphérique (Standard)
dispositif de lubrification	IR	Via inner ring lubrication hole

dimensions principale & données de performance

D	30 mm	Diamètre extérieur
F	14 mm	Diamètre de piste bague intérieure
C	13,8 mm	Largeur, bague extérieure
C _{r w}	6.100 N	Charge dyn. de base, radiale
C _{0r w}	6.900 N	Charge stat. de base, radiale
C _{ur w}	1.120 N	Limite à la fatigue, radiale
n _{D G}	5.500 1/min	Vitesse pour une lubrification à la graisse
≈m	61 g	Poids

Dimensions

d	10 mm	Alésage
B	14 mm	Largeur, bague intérieure
D _{1 min}	20 mm	Dimension de montage minimum
r _{min}	0,6 mm	Dimension minimum de chanfrein
r _{1 min}	0,3 mm	Dimension minimum de chanfrein
R	500 mm	Rayon bague extérieure profile externe



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés